


# EuropacPRO Cover Plate, Universal

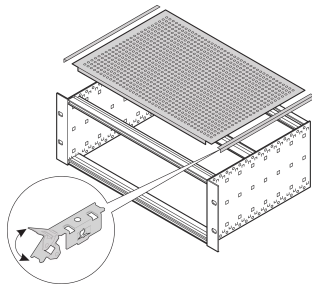

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be used is non-standard boards will be assembled into the subrack.

## CERTIFICATIONS



## FEATURES

Shielding is provided by optional EMC stainless steel gaskets, between cover plate and side panel

For variable positioning of horizontal rails e.g. for PCBs with non-standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Product Type:</b>	Cover Plate
<b>Product Family:</b>	EuropacPRO
<b>Finish:</b>	Passivated
<b>Works With:</b>	Subracks
<b>Type:</b>	Universal

Table 1/1

Catalog Number	Rack Width	Depth	Package Quantity	Package Unit	Quick Ship
24560-031	42HP	175mm	2	Pair	No

Catalog Number	Rack Width	Depth	Package Quantity	Package Unit	Quick Ship
24560-032	42HP	235mm	2	Pair	No
24560-033	42HP	295mm	2	Pair	No
24560-041	63HP	175mm	2	Pair	No
24560-042	63HP	235mm	2	Pair	No
24560-043	63HP	295mm	2	Pair	No
24560-051	84HP	175mm	2	Pair	No
24560-052	84HP	235mm	2	Pair	No
24560-053	84HP	295mm	2	Pair	No
24560-054	84HP	355mm	2	Pair	No
24560-055	84HP	415mm	2	Pair	No
24560-056	84HP	475mm	2	Pair	No

## ADDITIONAL PRODUCT DETAILS

---

In addition, 4 contact strips per subrack are required to affix cover to horizontal rail.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**