


# Panhead Screw, Pozidrive

Panhead Screw, Pozidrive.

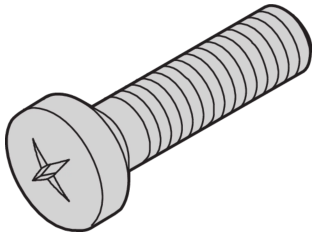

## CERTIFICATIONS



## FEATURES

Panhead screw, pozidrive

## SPECIFICATIONS

**Product Type:** Screw

**Material:** Steel

Table 1/2

Catalog Number	Diameter	Length	Finish	Package Quantity	Thread Size	Product Family
21101-314		5mm	Nickel Plated	100	M2.5	
21101-219		6mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-069		8mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-221		12mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit

CatalogNumber	Diameter	Length	Finish	Package Quantity	Thread Size	Product Family
21101-220		10mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21102-024	3mm	6mm	Zinc Plated	100	M3	
21101-222		16mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21100-788		12mm	Zinc Plated	100	M5	EuropacPRO
21120-150	5mm	10mm	Zinc Plated	100	M5	
21100-021	6mm	16mm	Zinc Plated	50	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21100-650	6mm	16mm	Zinc Plated	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21100-022	6mm	16mm	Zinc Plated	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO

Table 2/2

Catalog Number	Type	Works With	Thread Type	Quick Ship
21101-314	Panhead Screw	Backplanes, Test Adapters		No
21101-219	Panhead Screw	Backplanes, Test Adapters		No
21101-069	Panhead Screw	Backplanes, Test Adapters		No

Catalog Number	Type	Works With	Thread Type	Quick Ship
21101-221	Panhead Screw	Backplanes, Test Adapters		No
21101-220	Panhead Screw	Backplanes, Test Adapters		No
21102-024	Panhead Screw		Metric	No
21101-222	Panhead Screw	Backplanes, Test Adapters		No
21100-788	Panhead Screw	Subracks		No
21120-150	Coding Block	Cabinet		No
21100-021	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		No
21100-650	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		No
21100-022	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**