

H-Ti/T Rod to Flange Clip



CERTIFICATIONS



FEATURES

Suspends threaded rod from beam flanges

Threaded rod hanger can swivel to provide a vertical dropdown

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Static Load	Certifications
M6Ti24	174820	6 mm	Threaded	3 - 8 mm	900N	ITB
M6Ti24R5	191024	6 mm	Threaded	3 - 8 mm	900N	
M10Ti24	175000	10 mm	Threaded	3 - 8 mm	900N	ITB

CatalogNumber	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Static Load	Certifications
M8TI24	174910	8 mm	Threaded	3 - 8 mm	900N	ITB
M8TI58	174920	8 mm	Threaded	8 - 14 mm	900N	ITB
M6TI58R5	191025	6 mm	Threaded	8 - 14 mm	900N	
M10TI58	175010	10 mm	Threaded	8 - 14 mm	900N	ITB

DIAGRAMS

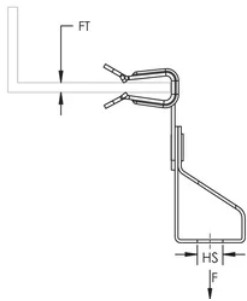

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

