

300M Universal Beam Clamp



CERTIFICATIONS



FEATURES

Universal beam clamp for standard beams

Structural attachment (with infinite adjustment) to top or bottom flange of metal beams to support hanger rod

Including set screw and lock nut

SPECIFICATIONS

Material: Cast Iron
Finish: Electrogalvanized
Hole Type: Threaded

Table 1/2

Catalog Number	Article Number	Thread Size (TS)	Flange Thickness (FT)	A	Torque (TQ)	Static Load
300M6	386805	M6	18 mm Max	21 mm	14 N·m Min	1200N
300M8	386810	M8	18 mm Max	21 mm	14 N·m Min	1200N


Table 2/2

Catalog Number	Article Number	Certifications
300M6	386805	
300M8	386810	ITB, VdS G4005005

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

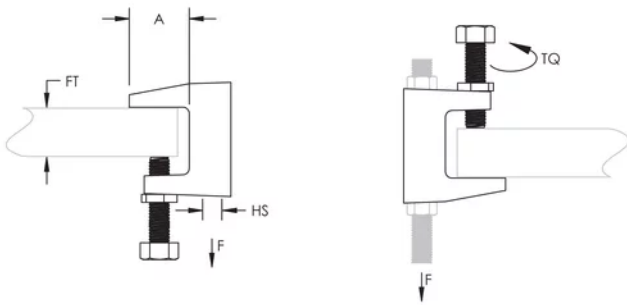

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

