

Hex Head Bolt, Imperial Thread



FEATURES

Imperial-threaded hex head bolt

SPECIFICATIONS


Material: Stainless Steel 18-8 (EN 1.4305)

Table 1/1

Catalog Number	Thread Size (TS)	Screw Length (L)
A927F177	1/4" UNC	12.7mm
A927F187	5/16" UNC	19mm
A927F193	3/8" UNC	19mm
A927F179	1/4" UNC	19mm
A927F181	1/4" UNC	25.4mm
A927F189	5/16" UNC	25.4mm
A927F195	3/8" UNC	25.4mm

Catalog Number	Thread Size (TS)	Screw Length (L)
A927F199	1/2" UNC	25.4mm
A927F201	1/2" UNC	38.1mm
A927F203	1/2" UNC	50.8mm
A927F183	1/4" UNC	31.75mm
A927F185	1/4" UNC	38.1mm
A927F236	5/16" UNC	31.75mm
A927F191	5/16" UNC	38.1mm
A927F197	3/8" UNC	38.1mm

DIAGRAMS

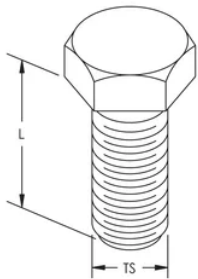

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE