



Stamped Crimp Cable T-Connector

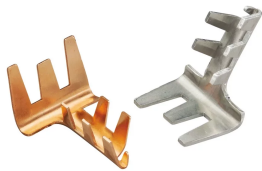

CERTIFICATIONS

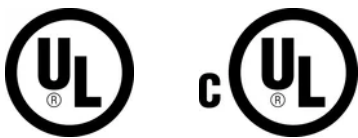

FEATURES

Connector with compression type fingers to crimp over cable


SPECIFICATIONS

Conductor Size, UL: Class 1

Table 1/1

Catalog Number	Material	Finish	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA501	Aluminum		50.8mm	32.77 mm	80.77 mm	0.02 kg
LPC501L	Copper	Tinned	50.8mm	32.77 mm	80.77 mm	0.04 kg
LPC501	Copper		50.8mm	32.77 mm	80.77 mm	0.04 kg

DIAGRAMS

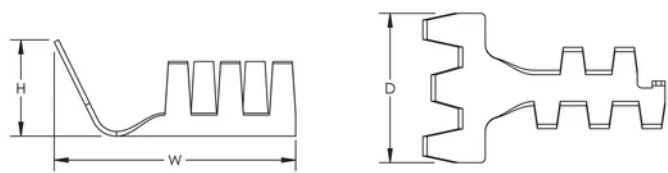

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE