

Rebar Grounding Clamp, Parallel

Power Utilities



CERTIFICATIONS



FEATURES

Universal use for rebar, rods or pipes

Lay-in feature cuts installation time

Bronze alloy construction with Stainless Steel 304 screws


Approved for direct burial in earth and concrete

SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Ground Rod Diameter, Actual (Ø)	Water Pipe Size (Ø)	Rebar Size, Metric
EK16	710355	12.7 – 25.4 mm	12.7 – 25.4 mm	12 – 25 mm

DIAGRAMS

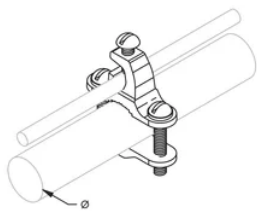

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE