


Front Panel, Unshielded, Screw Assembly 6 U, 2 HP, 2.5 mm, Al, Anodized

CATALOG NUMBER

30818-741

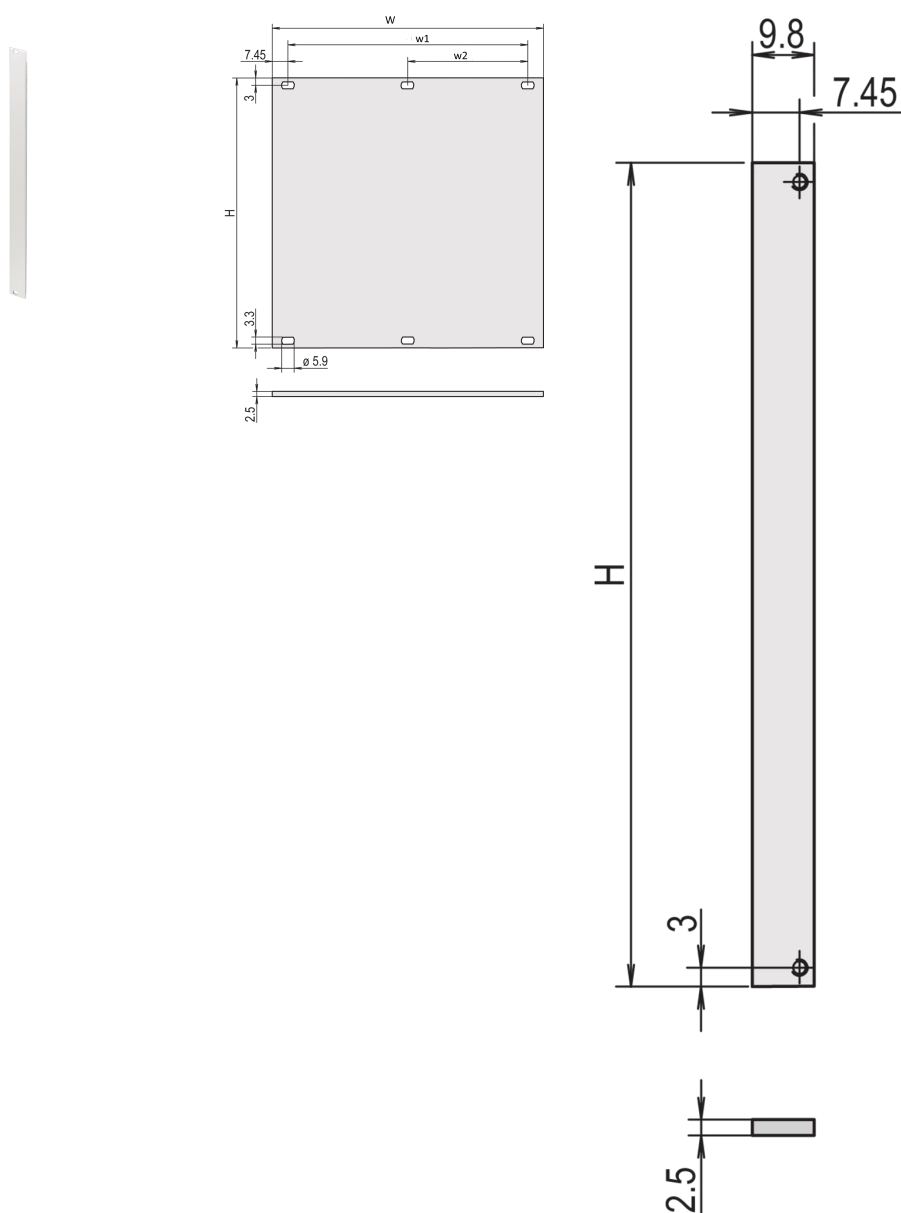

Anodized front panel, unshielded version, Al, 2.5 mm.

CERTIFICATIONS



FEATURES

Partial width front panel, Al, 2.5 mm
Al, anodized


PRODUCT ATTRIBUTES

Rack Height: 6U
Rack Width: 2HP
Package Quantity: 1
Accessory Type: Front panel
Mounting: Screw-on Front
Front Finish: Anodized
Rear Finish: Anodized
Treated Edges: Yes
Complies With: IEC 60297-3-101; IEEE 1101.1/10
Depth (D): 2.5mm
EMC Shielding: No
Finish: Anodized
Height (H): 261.8mm
Material: Aluminum
Product Type: Front Panel
Type: Front Panel without Handle
Width (W): 9.8mm
Net Weight: 0.02kg

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

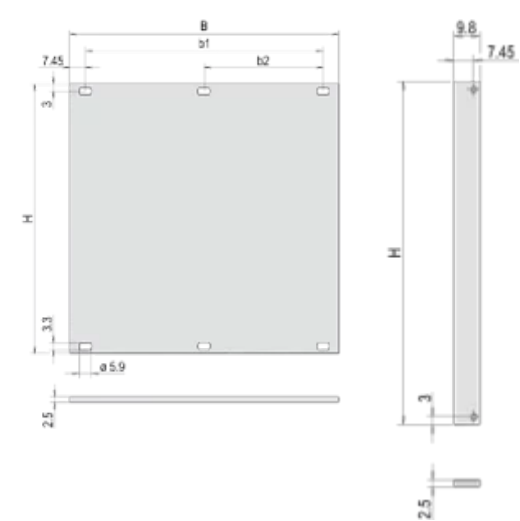

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE