


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

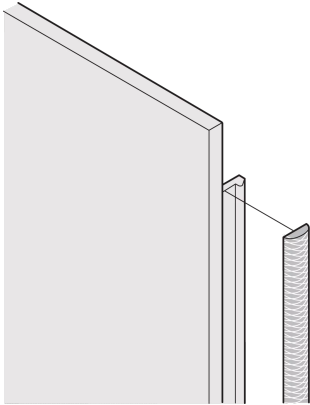

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

CERTIFICATIONS



FEATURES

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

SPECIFICATIONS

- Works With:** Subracks; Cases; Front Panels
- Product Family:** EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit
- Product Type:** Shielding Kit
- Material:** Thermoplastic Elastomer

Table 1/2

| Catalog Number | Rack Height | Package Quantity | Depth (D) | Height (H) | Width (W) | Flammability Rating |
|----------------|-------------|------------------|-----------|------------|-----------|---------------------|
|----------------|-------------|------------------|-----------|------------|-----------|---------------------|

| | | | | | | |
|-----------|----|-----|--------|---------|-------|-----------|
| 21101-853 | 3U | 10 | 1.62mm | 97mm | 3.8mm | UL® 94V-0 |
| 21101-855 | 6U | 10 | 1.62mm | 232mm | 3.8mm | UL® 94V-0 |
| 21101-857 | 2U | 10 | 1.62mm | 52mm | 3.8mm | UL® 94V-0 |
| 21101-859 | 9U | 10 | 1.62mm | 365.5mm | 3.8mm | UL® 94V-0 |
| 21101-854 | 3U | 100 | 1.62mm | 97mm | 3.8mm | UL® 94V-0 |
| 21101-856 | 6U | 100 | 1.62mm | 232mm | 3.8mm | UL® 94V-0 |
| 21101-858 | 4U | 10 | | | | |
| 21101-978 | 5U | 10 | | | | |
| 21101-904 | 9U | 100 | | | | |


Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 21101-853 | No |
| 21101-855 | No |
| 21101-857 | No |
| 21101-859 | No |
| 21101-854 | No |
| 21101-856 | No |
| 21101-858 | No |
| 21101-978 | No |
| 21101-904 | No |

ADDITIONAL PRODUCT DETAILS

EMC gaskets (textile) are required for shielding the front panels.

DIAGRAMS

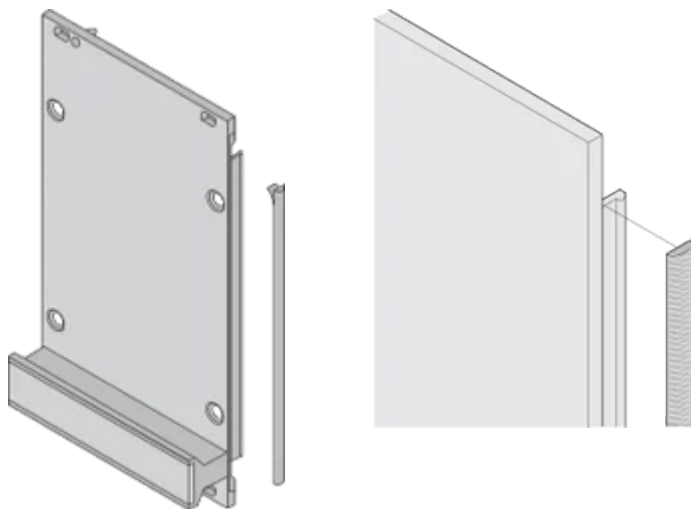

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE