

# nVent CADDY Rod Lock Anchor Screw



## CERTIFICATIONS



## FEATURES

For use with concrete and solid brick

Prefabricated assemblies easily lift and lock into place, helping to save time and money

Easy "push-to-install" design allows installers to simply push the threaded rod through the mounting hole, instantly holding it in position

Works with slightly damaged threads and minor burrs on the threaded rod

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel


Table 1/2

Catalog Number	Article Number	Rod Size (RS)	B	C	Length (L)	Drill Bit Diameter
CRLAM8EG	390009	8	32 mm	22 mm	72mm	8mm
CRLAM10EG	390010	10	32 mm	22 mm	72mm	8mm

Table 2/2

Catalog Number	Article Number	Drill Hole Depth	Static Load	Certifications
CRLAM8EG	390009	50mm	2900N	ITB
CRLAM10EG	390010	50mm	2900N	ITB, FM Approved, Pipe Hanger Components

## DIAGRAMS

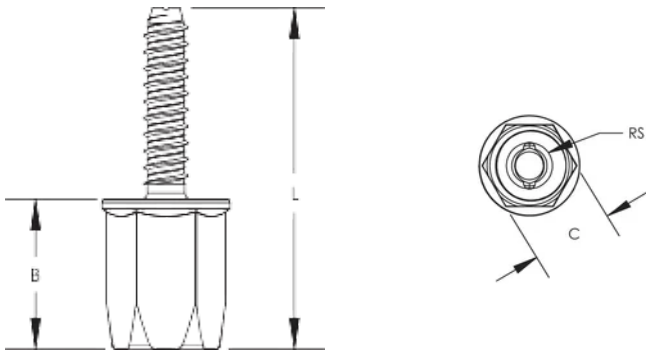

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

