

# Drill Distance Gauge, Four Plates



## FEATURES

Used for making precise drill hole spacings of  $\pm 1$  mm (0.039")

Common applications include fishplates and insulated rail joints

## SPECIFICATIONS

**Drill Guide Included:** No

**Material:** Steel

Table 1/2


Catalog Number	Article Number	Rail Type	Length (L)	Width (W)	Height (H)	A
DDGNP4AM40	716553	NP4AM	400mm	87.9 mm	50 mm	40 mm
DDGNP4AM45	716554	NP4AM	415mm	87.9 mm	50 mm	45 mm
DDG750900750	716552	STR40	520mm	87.9 mm	50 mm	75 mm
DDG570660570	715268	S49	375mm	119.9 mm	60 mm	57 mm

Table 2/2

Catalog Number	Article Number	B	C
DDGNP4AM40	716553	40 mm	40 mm

Catalog Number	Article Number	B	C
DDGNP4AM45	716554	45 mm	45 mm
DDG750900750	716552	90 mm	75 mm
DDG570660570	715268	66 mm	57 mm

## DIAGRAMS

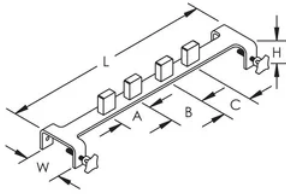

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**