 


Mild Steel IP Protected LCT Rack, MCI



The mild steel combinable floor standing ICT enclosure range, MCI, is made up of integrated 19" profiles and a rear door. It is an ideal solution for ICT applications, and requires only limited assembly time, since the profiles are pre-mounted. Procurement is made easy with only one single item number for the whole solution.

INDUSTRY STANDARDS

cULus_UL Listed

CE UKCA

EAC

GOST

FEATURES

Material: Frame: 1.5 mm steel plate. Door: 2 mm steel plate. Roof plate: 1.5 mm steel plate. Bottom plates: 1 mm galvanized steel. 19" profiles: 2 mm zinc plated steel

Frame: Seam welded reversed open profiles with 25 mm hole pattern, according to DIN 43660. Including integrated external hole pattern

Rear door: Mounted with hinges, allowing left or right hand opening. Including door frame with 25 mm hole pattern

Side panels: Supplied as an accessory

Roof panel: Removable

Lock: Espagnolette 4-point locking system. Does not interfere with the enclosure inner space. Standard double-bit lock with 3 mm insert. Standard inserts, cylinders, lift handles and T-handles are available as accessories

Bottom plates: Consists of three or four (D>600) pieces

19" profiles: Provides front and side universal 19" hole pattern. Adjustable in depth by steps of 25 mm

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud

Finish: Frame, rear door and roof plate: RAL 7035 structured powder coating. 19" profiles: zinc plated steel

Protection: Complies with IP 55 | TYPE 12 | IK 10, when plain front door and side panels are fitted

Mounting requirements: Add side panels for closed sides. Front frame can be covered with FFC or fitted with a glazed or plain door


Delivery: Frame with fitted rear door, roof panel, bottom plates. 19" profiles at front and fixing brackets CIB. For enclosures 2200 mm height, delivery includes two CMB profiles mounted in depth. Delivery also includes earthing bolts. Delivered on a pallet which is identical to the width of the enclosure to allow baying without removal. All packing material is recyclable.

SPECIFICATIONS

Body Thickness:	1.5mm
Door Thickness:	2mm
Color:	Light Gray
Material:	Mild Steel
Finish:	Powder Coated; Zinc Plated
Color Code:	RAL 7035

Table 1/1					
Catalog Number	Height (H)	Width (W)	Depth (D)	Rack Units	Quick Ship
MCI11066R5	1100mm	600mm	600mm	22U	No
MCI14086R5	1400mm	800mm	600mm	29U	No
MCI16066R5	1600mm	600mm	600mm	33U	No
MCI18066R5	1800mm	600mm	600mm	38U	No
MCI18068R5	1800mm	600mm	800mm	38U	No
MCI18086R5	1800mm	800mm	600mm	38U	No
MCI20066R5	2000mm	600mm	600mm	42U	No
MCI20068R5	2000mm	600mm	800mm	42U	No
MCI20086R5	2000mm	800mm	600mm	42U	No
MCI20088R5	2000mm	800mm	800mm	42U	No
MCI22066R5	2200mm	600mm	600mm	47U	No
MCI22068R5	2200mm	600mm	800mm	47U	No
MCI22086R5	2200mm	800mm	600mm	47U	No
MCI22088R5	2200mm	800mm	800mm	47U	No

DIAGRAMS

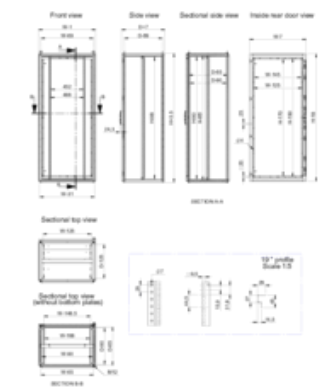

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE