


# 19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.

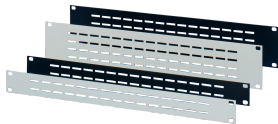

## CERTIFICATIONS



## FEATURES

Vented front panels (Aluminum ) allows heat dissipation

## SPECIFICATIONS

<b>Rack Width:</b>	95HP
<b>Material:</b>	Aluminum
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/3

Catalog Number	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30118-962	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized

CatalogNumber	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30702-056	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30118-964	3U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-058	3U	Powder Coated	Screw-on Front	1	Painted	Painted

Table 2/3

Catalog Number	Treated Edges	Color Code	EMC Shielding	Height (H)	Type	Width (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm

CatalogNumber	Treated Edges	Color Code	EMC Shielding	Height (H)	Type	Width (W)
30702-046			No	132.5mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm


Table 3/3

Catalog Number	Quick Ship
30118-962	No
30702-044	No
30702-047	No
30702-056	No
30118-963	No
30118-964	No
30702-045	No
30702-046	No
30702-048	No
30702-049	No
30702-057	No
30702-058	No

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

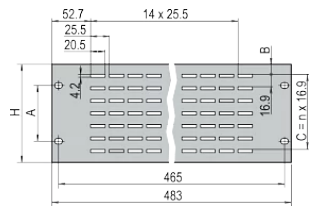

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE