


Varistar CP Double Steel Door, Perforated, 3-Point Locking

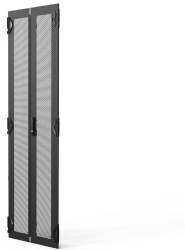

Perforated Varistar CP steel double door with 3-point locking for applications with IP 20 protection

FEATURES

Double perforated steel door with 3 point locking for IP 20 protection class

Lever handle with key insert (2 keys)

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with lever handle 24630003 and DIN profile half cylinder with keys or push button

SPECIFICATIONS

Locking Type: 3-Point Locking

Product Type: Cabinet Door

Protection Rating: IP20

Material: Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-448	24U	1200mm	600mm	1	Black Grey	RAL 7021
21630-449	24U	1200mm	800mm	1	Black Grey	RAL 7021
21630-450	29U	1400mm	600mm	1	Black Grey	RAL 7021

CatalogNumber	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-451	29U	1400mm	800mm	1	Black Grey	RAL 7021
21630-452	33U	1600mm	600mm	1	Black Grey	RAL 7021
21630-453	33U	1600mm	800mm	1	Black Grey	RAL 7021
21630-454	38U	1800mm	600mm	1	Black Grey	RAL 7021
21630-455	38U	1800mm	800mm	1	Black Grey	RAL 7021
21630-020	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-027	42U	2000mm	800mm	1	Black Grey	RAL 7021
21630-021	47U	2200mm	600mm	1	Black Grey	RAL 7021
21630-028	47U	2200mm	800mm	1	Black Grey	RAL 7021
21630-022	52U	2450mm	600mm	1	Black Grey	RAL 7021
21630-029	52U	2450mm	800mm	1	Black Grey	RAL 7021

Table 2/2					
Catalog Number	Complies With	Finish	Type	Works With	Quick Ship
21630-448	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-449	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-450	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-451	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-452	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-453	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No

Catalog Number	Complies With	Finish	Type	Works With	Quick Ship
21630-454	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-455	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-020	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-027	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-021	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-028	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-022	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-029	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP	No

ADDITIONAL PRODUCT DETAILS

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE