

BH Bell Hanger Pipe Clamp



FEATURES

Mounting screw is recessed and has a pierce-point to penetrate metal studs

SPECIFICATIONS


Finish: Copper Electroplated

Material: Steel

Table 1/1

Catalog Number	NB/DN	Outer Diameter (OD)	A	B
BH0050CP	15	21.3 mm	19 mm	40.6 mm
BH0075CP	20	26.9 mm	19 mm	43.2 mm
BH0100CP	25	33.7 mm	19 mm	44.5 mm

DIAGRAMS

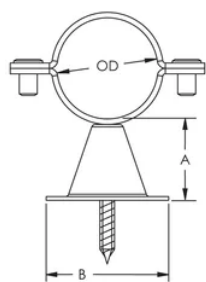

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

