

PEMSA Wire Basket Tray Shelf Support



CERTIFICATIONS



FEATURES

Easy to use, quick connect feature

IEC 61537 load rating and earthing compliant

Ideal for higher load installations

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Table 1/1

Catalog Number	Article Number	Length (L)	Width (W)	Height (H)	Hole Size (HS)	Static Load
WBT400SHLFS PRT	820140	430mm	35 mm	126 mm	11 - 14 mm	1765N
WBT150SHLFS PRT	820110	180mm	35 mm	90 mm	11 - 14 mm	1667N

CatalogNumber	Article Number	Length (L)	Width (W)	Height (H)	Hole Size (HS)	Static Load
WBT200SHLFS PRT	820120	230mm	35 mm	90 mm	11 - 14 mm	1765N
WBT100SHLFS PRT	820100	130mm	35 mm	90 mm	11 - 14 mm	2059N
WBT300SHLFS PRT	820130	330mm	35 mm	90 mm	11 - 14 mm	1373N

DIAGRAMS

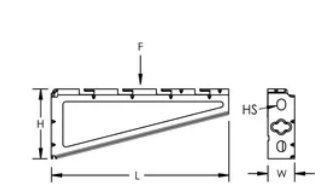

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

