

U-Bolt



FEATURES

Complete with 4 nuts

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N017M6	599110	Steel	Electrogalvanized	17 mm	10	M6
UB4N021M6	599120	Steel	Electrogalvanized	21 mm	15	M6
UB4N021M8S6	599346	Stainless Steel 316 (EN 1.4401)		21 mm	15	M8
UB4N027M8	599130	Steel	Electrogalvanized	27 mm	20	M8
UB4N027M8S6	597615	Stainless Steel 316 (EN 1.4401)		27 mm	20	M8
UB4N034M8	599140	Steel	Electrogalvanized	34 mm	25	M8
UB4N042M8	599150	Steel	Electrogalvanized	42 mm	32	M8

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N049M8	599160	Steel	Electrogalvanized	49 mm	40	M8
UB4N049M8S6	597645	Stainless Steel 316 (EN 1.4401)		49 mm	40	M8
UB4N042M8S6	597635	Stainless Steel 316 (EN 1.4401)		42 mm	32	M8
UB4N060M8S6	597655	Stainless Steel 316 (EN 1.4401)		60 mm	50	M8
UB4N076M8	599180	Steel	Electrogalvanized	76 mm	65	M8
UB4N076M8S6	597665	Stainless Steel 316 (EN 1.4401)		76 mm	65	M8
UB4N090M10	599190	Steel	Electrogalvanized	90 mm	80	M10
UB4N090M8S6	599357	Stainless Steel 316 (EN 1.4401)		90 mm	80	M8
UB4N114M10	599200	Steel	Electrogalvanized	114 mm	100	M10
UB4N114M8S6	599348	Stainless Steel 316 (EN 1.4401)		114 mm	100	M8
UB4N140M8	599337	Steel	Electrogalvanized	140 mm	125	M8
UB4N140M8S6	599350	Stainless Steel 316 (EN 1.4401)		140 mm	125	M8
UB4N160M8	599338	Steel	Electrogalvanized	160 mm		M8
UB4N160M8S6	599351	Stainless Steel 316 (EN 1.4401)		160 mm		M8
UB4N168M14	599240	Steel	Electrogalvanized	168 mm	150	M14
UB4N168M8S6	599352	Stainless Steel 316 (EN 1.4401)		168 mm	150	M8

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N219M10	599341	Steel	Electrogalvanized	219 mm	200	M10
UB4N219M10S6	599354	Stainless Steel 316 (EN 1.4401)		219 mm	200	M10
UB4N219M16	599250	Steel	Electrogalvanized	219 mm	200	M16
UB4N273M10S6	599355	Stainless Steel 316 (EN 1.4401)		273 mm	250	M10
UB4N273M16	599260	Steel	Electrogalvanized	273 mm	250	M16
UB4N323M10	599343	Steel	Electrogalvanized	323 mm	300	M10
UB4N323M10S6	599356	Stainless Steel 316 (EN 1.4401)		323 mm	300	M10


Table 2/2

Catalog Number	Article Number	Height (H)
UB4N017M6	599110	42 mm
UB4N021M6	599120	46 mm
UB4N021M8S6	599346	46 mm
UB4N027M8	599130	58 mm
UB4N027M8S6	597615	58 mm
UB4N034M8	599140	63 mm
UB4N042M8	599150	76 mm
UB4N049M8	599160	78 mm
UB4N049M8S6	597645	78 mm

Catalog Number	Article Number	Height (H)
UB4N042M8S6	597635	76 mm
UB4N060M8S6	597655	88 mm
UB4N076M8	599180	118 mm
UB4N076M8S6	597665	118 mm
UB4N090M10	599190	125 mm
UB4N090M8S6	599357	125 mm
UB4N114M10	599200	166 mm
UB4N114M8S6	599348	166 mm
UB4N140M8	599337	197 mm
UB4N140M8S6	599350	197 mm
UB4N160M8	599338	214 mm
UB4N160M8S6	599351	214 mm
UB4N168M14	599240	224 mm
UB4N168M8S6	599352	224 mm
UB4N219M10	599341	286 mm
UB4N219M10S6	599354	286 mm
UB4N219M16	599250	286 mm
UB4N273M10S6	599355	331 mm

Catalog Number	Article Number	Height (H)
UB4N273M16	599260	331 mm
UB4N323M10	599343	389 mm
UB4N323M10S6	599356	389 mm

DIAGRAMS

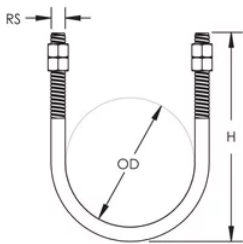

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

