

# FS Spacer Clamp



## CERTIFICATIONS



## FEATURES

Provides support for nVent ERIFLEX Flexibar and insulated braided conductors without damaging the insulation

Ensures correct spacing for optimum cooling

Supports up to four conductors in parallel

Easy to install

Spacers are halogen free

RoHS compliant

## SPECIFICATIONS

|                             |                   |
|-----------------------------|-------------------|
| <b>Finish:</b>              | Electrogalvanized |
| <b>Material:</b>            | Steel;Polyamide   |
| <b>Flammability Rating:</b> | UL® 94HB          |
| <b>Working Temperature:</b> | -40 to 130 °C     |

Table 1/2

| Catalog Number | Article Number | Conductor Width | Height (H) | Length (L) | Hole Size (HS) | A |
|----------------|----------------|-----------------|------------|------------|----------------|---|
|----------------|----------------|-----------------|------------|------------|----------------|---|


|          |        |             |        |       |        |        |
|----------|--------|-------------|--------|-------|--------|--------|
| FS40-63  | 553570 | 40 - 63 mm  | 95 mm  | 166mm | 8.5 mm | 150 mm |
| FS80-100 | 553580 | 80 - 100 mm | 140 mm | 224mm | 8.5 mm | 200 mm |

| Table 2/2      |                |             |
|----------------|----------------|-------------|
| Catalog Number | Article Number | Unit Weight |
| FS40-63        | 553570         | 0.1 kg      |
| FS80-100       | 553580         | 0.25 kg     |

### ADDITIONAL PRODUCT DETAILS

Recommended distance between supports is 400 mm (15 3/4").

### DIAGRAMS

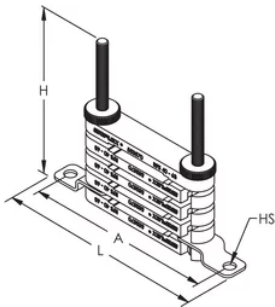

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**