


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

Power Utilities

CATALOG NUMBER

20848-617

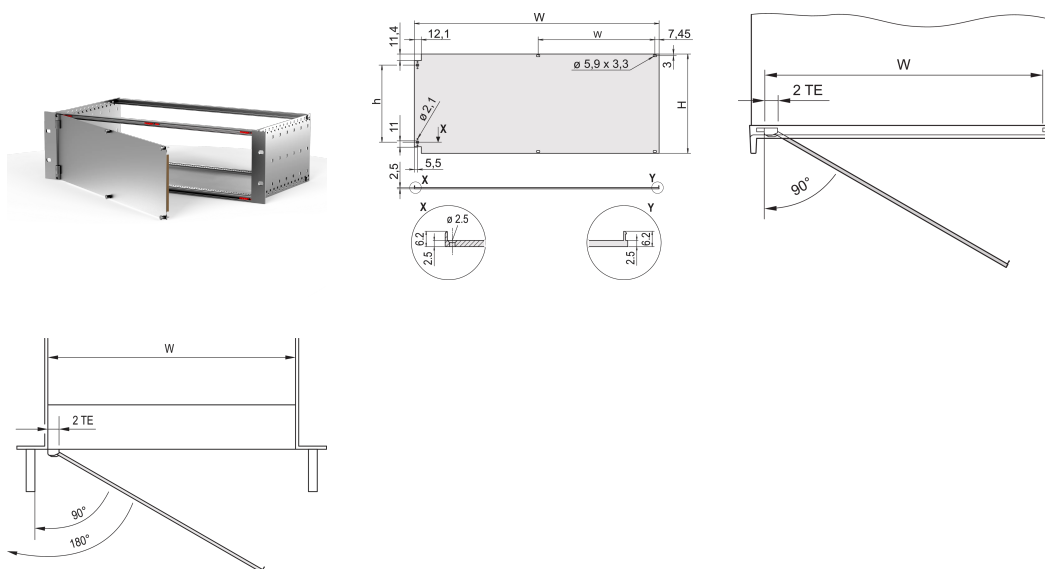

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICATIONS



FEATURES

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUCT ATTRIBUTES

Product Type: Front Panel
Type: Front Panel without Handle
Mounting: Hinged, Side
EMC Shielding: No (Retrofittable)
EMC Gasket Type: Textile
Material: Aluminum
Front Finish: Anodized
Rear Finish: Conductive
Treated Edges: No
Rack Height: 6 U
Height: 261.8 mm
Rack Width: 84 HP
Width: 426.4 mm
Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE