


# PSU Front Panel

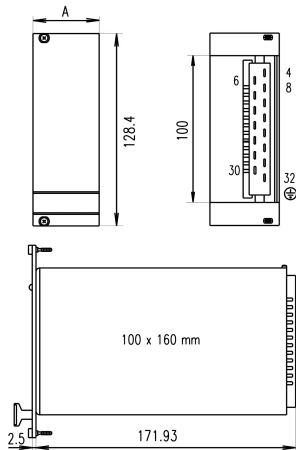

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

## CERTIFICATIONS



## FEATURES

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

## SPECIFICATIONS

**Accessory Type:** Front panel

Table 1/2

| Catalog Number | Material | Front Finish | Rear Finish | Treated Edges | Rack Height | Height  |
|----------------|----------|--------------|-------------|---------------|-------------|---------|
| 21006-943      | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21006-945      | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |

| CatalogNumber | Material | Front Finish | Rear Finish | Treated Edges | Rack Height | Height  |
|---------------|----------|--------------|-------------|---------------|-------------|---------|
| 21006-954     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21006-959     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 31006-677     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21006-955     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21006-956     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21006-957     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-475     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-473     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-474     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-476     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-477     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-478     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-470     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-451     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |
| 21005-439     | Aluminum | Anodized     | Conductive  | No            | 3U          | 128.4mm |

Table 2/2

| Catalog Number | Rack Width | Width   | Depth | Package Quantity | Finish   | Quick Ship |
|----------------|------------|---------|-------|------------------|----------|------------|
| 21006-943      | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21006-945      | 8HP        | 40.3mm  | 2.5mm | 1                | Anodized | No         |

| CatalogNumber | Rack Width | Width   | Depth | Package Quantity | Finish   | Quick Ship |
|---------------|------------|---------|-------|------------------|----------|------------|
| 21006-954     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21006-959     | 3HP        | 14.9mm  | 2.5mm | 1                | Anodized | No         |
| 31006-677     | 8HP        | 40.3mm  | 2.5mm | 1                | Anodized | No         |
| 21006-955     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21006-956     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21006-957     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21005-475     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21005-473     | 10HP       | 50.46mm | 2.5mm | 1                | Anodized | No         |
| 21005-474     | 14HP       | 70.78mm | 2.5mm | 1                | Anodized | No         |
| 21005-476     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21005-477     | 10HP       | 50.46mm | 2.5mm | 1                | Anodized | No         |
| 21005-478     | 14HP       | 70.78mm | 2.5mm | 1                | Anodized | No         |
| 21005-470     | 6HP        | 30.14mm | 2.5mm | 1                | Anodized | No         |
| 21005-451     | 10HP       | 50.46mm | 2.5mm | 1                | Anodized | No         |
| 21005-439     | 14HP       | 70.78mm | 2.5mm | 1                | Anodized | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**