

4G24 Twist Clip with Stud



CERTIFICATIONS



FEATURES

Supports electrical fixtures from acoustical T-grid

No tools required for installation

Fast, easy and secure twist-on installation

Designed to reduce scratching of T-grid

Nut sold separately

SPECIFICATIONS

Material: Spring Steel;Steel

Table 1/2


Catalog Number	Article Number	Finish	Color	Screw Length (L)	Flange Thickness (FT)	T-Grid Size
4G24M16WHSP 25	172290	Painted	White	16mm	1.5 mm	24mm
4G24M11WH	171840	Painted	White	11mm	1.5 mm	24mm

CatalogNumber	Article Number	Finish	Color	Screw Length (L)	Flange Thickness (FT)	T-Grid Size
4G24M25WHSP 25	172300	Painted	White	25mm	1.5 mm	24mm
4G24M16	171710	nVent CADDY Armour	Gray	16mm	1.5 mm	24mm
4G24M25	171730	nVent CADDY Armour	Gray	25mm	1.5 mm	24mm
4G24M11	171680	nVent CADDY Armour	Gray	11mm	1.5 mm	24mm
4G24M16WH	171860	Painted	White	16mm	1.5 mm	24mm

Table 2/2

Catalog Number	Article Number	Screw Diameter (Sc)	Static Load
4G24M16WHSP25	172290	6	220N
4G24M11WH	171840	6	220N
4G24M25WHSP25	172300	6	220N
4G24M16	171710	6	220N
4G24M25	171730	6	220N
4G24M11	171680	6	220N
4G24M16WH	171860	6	220N

DIAGRAMS

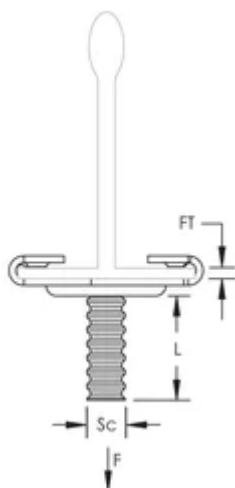

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

