

# 19" Front Panel With Holes for Handles



Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

## CERTIFICATIONS



## FEATURES

19" front panels have additional holes for mounting of handles

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 95HP        |
| <b>Material:</b>       | Aluminum    |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |

Table 1/3

| Catalog Number | Rack Height | Depth (D) | Handle Type  | Finish   | Mounting       | Package Quantity |
|----------------|-------------|-----------|--------------|----------|----------------|------------------|
| 30219-161      | 1U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 40304-050      | 1U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 30219-162      | 2U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |

| CatalogNumber | Rack Height | Depth (D) | Handle Type  | Finish   | Mounting       | Package Quantity |
|---------------|-------------|-----------|--------------|----------|----------------|------------------|
| 30219-163     | 3U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 30219-164     | 4U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 30219-165     | 5U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 30219-166     | 6U          |           | Front Handle | Anodized | Screw-on Front | 1                |
| 40304-051     | 2U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 40304-052     | 3U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 40304-053     | 4U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 40304-054     | 5U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |
| 40304-055     | 6U          | 3mm       | Front Handle | Anodized | Screw-on Front | 1                |

Table 2/3


| Catalog Number | Front Finish | Rear Finish | Treated Edges | EMC Shielding | Height (H) | Type            |
|----------------|--------------|-------------|---------------|---------------|------------|-----------------|
| 30219-161      | Anodized     | Anodized    | No            | No            | 43.6mm     | 19" Front Panel |
| 40304-050      | Anodized     | Anodized    | Yes           | No            | 43.6mm     | 19" Front Panel |
| 30219-162      | Anodized     | Anodized    | No            | No            | 88.1mm     | 19" Front Panel |
| 30219-163      | Anodized     | Anodized    | No            | No            | 132.5mm    | 19" Front Panel |
| 30219-164      | Anodized     | Anodized    | No            | No            | 177mm      | 19" Front Panel |
| 30219-165      | Anodized     | Anodized    | No            | No            | 221.4mm    | 19" Front Panel |
| 30219-166      | Anodized     | Anodized    | No            | No            | 265.9mm    | 19" Front Panel |

| CatalogNumber | Front Finish | Rear Finish | Treated Edges | EMC Shielding | Height (H) | Type            |
|---------------|--------------|-------------|---------------|---------------|------------|-----------------|
| 40304-051     | Anodized     | Anodized    | Yes           | No            | 88.1mm     | 19" Front Panel |
| 40304-052     | Anodized     | Anodized    | Yes           | No            | 132.5mm    | 19" Front Panel |
| 40304-053     | Anodized     | Anodized    | Yes           | No            | 177mm      | 19" Front Panel |
| 40304-054     | Anodized     | Anodized    | Yes           | No            | 221.4mm    | 19" Front Panel |
| 40304-055     | Anodized     | Anodized    | Yes           | No            | 265.9mm    | 19" Front Panel |

Table 3/3

| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30219-161      | 483mm     | No         |
| 40304-050      | 483mm     | No         |
| 30219-162      | 483mm     | No         |
| 30219-163      | 483mm     | No         |
| 30219-164      | 483mm     | No         |
| 30219-165      | 483mm     | No         |
| 30219-166      | 483mm     | No         |
| 40304-051      | 483mm     | No         |
| 40304-052      | 483mm     | No         |
| 40304-053      | 483mm     | No         |
| 40304-054      | 483mm     | No         |
| 40304-055      | 483mm     | No         |

DIAGRAMS

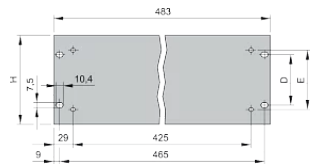

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE