


# Interscale Fan Holder With Fans

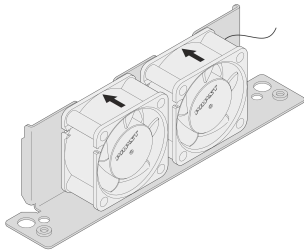

Interscale Fan Holder With Fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m³/h.

## FEATURES

Fan holder for mounting on bottom of case

Fans are simple to fit to the fan holder using vibration-damping fixing material

Fan holders fix into desktop case with 2 plastic feet or into 19" case with 2 screws

Fan holder cannot be used in conjunction with the mounting plate (instead use mounting plate with integrated fan holder)

For technical data of fans, please see delivery includes

## SPECIFICATIONS

**Finish:** Aluminum-Zinc Plated

**Type:** Fan Tray

**Product Type:** Fan Unit

**Input Voltage DC:** 12V min

Table 1/2

| Catalog Number | Width | Depth | Package Quantity | Max Static Pressure | Max Ambient Temperature | Airflow |
|----------------|-------|-------|------------------|---------------------|-------------------------|---------|
| 24828-104      | 40mm  | 20mm  | 1                |                     | 70°C                    | 10m³/h  |
| 24828-105      | 40mm  | 20mm  | 1                |                     | 70°C                    | 10m³/h  |
| 24828-107      | 40mm  | 20mm  | 1                |                     | 70°C                    | 10m³/h  |

| CatalogNumber | Width | Depth | Package Quantity | Max Static Pressure | Max Ambient Temperature | Airflow |
|---------------|-------|-------|------------------|---------------------|-------------------------|---------|
| 24828-204     | 80mm  | 25mm  | 1                |                     | 70°C                    | 19m³/h  |
| 24828-205     | 80mm  | 25mm  | 1                |                     | 70°C                    | 19m³/h  |
| 24828-207     | 80mm  | 25mm  | 1                |                     | 70°C                    | 19m³/h  |
| 24828-305     | 119mm | 25mm  | 1                |                     | 70°C                    | 170m³/h |
| 24828-307     | 119mm | 25mm  | 1                |                     | 70°C                    | 170m³/h |
| 24830-101     | 80mm  | 25mm  | 1                | 95.41Pa             | 70°C                    | 109m³/h |
| 24830-102     | 80mm  | 25mm  | 1                |                     |                         |         |

Table 2/2

| Catalog Number | Noise Level | Height | Material | Power | Product Family | Quick Ship |
|----------------|-------------|--------|----------|-------|----------------|------------|
| 24828-104      | 18dB(A)     | 40mm   | Steel    | 0.9W  | Interscale     | No         |
| 24828-105      | 18dB(A)     | 40mm   | Steel    | 0.9W  | Interscale     | No         |
| 24828-107      | 18dB(A)     | 40mm   | Steel    | 0.9W  | Interscale     | No         |
| 24828-204      | 32dB(A)     | 80mm   | Steel    | 2W    | Interscale     | No         |
| 24828-205      | 32dB(A)     | 80mm   | Steel    | 2W    | Interscale     | No         |
| 24828-207      | 32dB(A)     | 80mm   | Steel    | 2W    | Interscale     | No         |
| 24828-305      | 43dB(A)     | 119mm  | Steel    | 5.3W  | Interscale     | No         |
| 24828-307      | 43dB(A)     | 119mm  | Steel    | 5.3W  | Interscale     | No         |
| 24830-101      | 44.62dB(A)  | 80mm   | Steel    |       |                | No         |

| CatalogNumber | Noise Level | Height | Material | Power | Product Family | Quick Ship |
|---------------|-------------|--------|----------|-------|----------------|------------|
| 24830-102     |             | 80mm   | Steel    |       |                | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE