


# Novastar Base Plate, Multi Pieces, Open at Rear

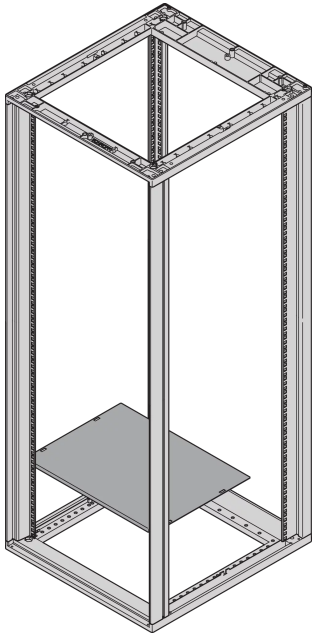

Base plate is a plain steel blanking plate fitted to the cabinet base. Restricts air-flow into the cabinet from floor cavity and can be opened for cable ducting.

## CERTIFICATIONS



## FEATURES

Base is open at rear for cable ducting; opening can be closed with a plain or perforated cover, filter plate or brush strip

Rear opening, width 440 mm, depth 70 mm

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Base

**Material:** Steel

Table 1/2

| Catalog Number | Width | Depth | Package Quantity | Color | Color Code | Finish |
|----------------|-------|-------|------------------|-------|------------|--------|
|----------------|-------|-------|------------------|-------|------------|--------|

|           |       |        |   |            |          |               |
|-----------|-------|--------|---|------------|----------|---------------|
| 27230-188 | 553mm | 500mm  | 1 | Black Grey | RAL 7021 | Powder Coated |
| 27230-192 | 553mm | 1000mm | 1 | Black Grey | RAL 7021 | Powder Coated |
| 27230-191 | 553mm | 900mm  | 1 | Black Grey | RAL 7021 | Powder Coated |
| 27230-190 | 553mm | 800mm  | 1 | Black Grey | RAL 7021 | Powder Coated |
| 27230-189 | 553mm | 600mm  | 1 | Black Grey | RAL 7021 | Powder Coated |

Table 2/2

| Catalog Number | Type       | Quick Ship |
|----------------|------------|------------|
| 27230-188      | Base Plate | No         |
| 27230-192      | Base Plate | No         |
| 27230-191      | Base Plate | No         |
| 27230-190      | Base Plate | No         |
| 27230-189      | Base Plate | No         |

## ADDITIONAL PRODUCT DETAILS

Please order cover plate or brush strip separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**