


Panhead Screw, Torx, Self-Securing

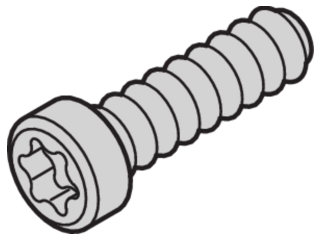

Pan head torx screws with different metric threads and lengths. With optional features like GND earthing function or self-securing thread.

CERTIFICATIONS



FEATURES

Pan Head Screw with torx, self-locking

SPECIFICATIONS

Type: Panhead Screw
Product Type: Screw
Material: Steel

Table 1/1

Catalog Number	Length	Finish	Package Quantity	Thread Size	Works With	Quick Ship
24560-159	6mm	Zinc Plated	100	M2.5	Backplanes, Test Adapters	No
21500-039	9.3mm	Zinc Plated	100	M2.5	Front Panels, Horizontal Rails, Type H, Horizontal Rails, Type R	No

ADDITIONAL PRODUCT DETAILS

Torque max. 0.2 Nm.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE