


# Varistar CP Mobile Frame

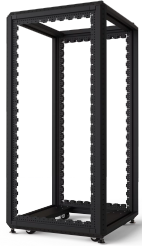

Varistar welded steel frame for static load requirements. For 19", ETSI or mounting plate integration. For mobile applications.

## FEATURES

Welded, finish powder-coated, black gray, RAL 7021

## SPECIFICATIONS

- Dynamic Load:** 1000kg
- Static Load:** 1600kg
- Product Type:** Cabinet/Rack Frame
- Material:** Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Depth	Package Quantity	Color
20630-252	52U	2450mm	600mm	1100mm	1	Black Grey
20630-255	52U	2450mm	800mm	1100mm	1	Black Grey
20630-231	42U	2000mm	600mm	1100mm	1	Black Grey
20630-232	42U	2000mm	600mm	1200mm	1	Black Grey
20630-237	42U	2000mm	800mm	1100mm	1	Black Grey
20630-238	42U	2000mm	800mm	1200mm	1	Black Grey

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>
20630-243	47U	2200mm	600mm	1100mm	1	Black Grey
20630-244	47U	2200mm	600mm	1200mm	1	Black Grey
20630-249	47U	2200mm	800mm	1100mm	1	Black Grey
20630-250	47U	2200mm	800mm	1200mm	1	Black Grey
20630-193	24U	1200mm	600mm	600mm	1	Black Grey
20630-194	24U	1200mm	600mm	800mm	1	Black Grey
20630-199	24U	1200mm	800mm	600mm	1	Black Grey
20630-200	24U	1200mm	800mm	800mm	1	Black Grey
20630-203	29U	1400mm	600mm	600mm	1	Black Grey
20630-204	29U	1400mm	600mm	800mm	1	Black Grey
20630-207	29U	1400mm	800mm	600mm	1	Black Grey
20630-208	29U	1400mm	800mm	800mm	1	Black Grey
20630-211	33U	1600mm	600mm	600mm	1	Black Grey
20630-212	33U	1600mm	600mm	800mm	1	Black Grey
20630-215	33U	1600mm	800mm	600mm	1	Black Grey
20630-216	33U	1600mm	800mm	800mm	1	Black Grey
20630-219	38U	1800mm	600mm	600mm	1	Black Grey
20630-220	38U	1800mm	600mm	800mm	1	Black Grey

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>
20630-223	38U	1800mm	800mm	600mm	1	Black Grey
20630-224	38U	1800mm	800mm	800mm	1	Black Grey
20630-227	42U	2000mm	600mm	600mm	1	Black Grey
20630-228	42U	2000mm	600mm	800mm	1	Black Grey
20630-229	42U	2000mm	600mm	900mm	1	Black Grey
20630-230	42U	2000mm	600mm	1000mm	1	Black Grey
20630-233	42U	2000mm	800mm	600mm	1	Black Grey
20630-234	42U	2000mm	800mm	800mm	1	Black Grey
20630-235	42U	2000mm	800mm	900mm	1	Black Grey
20630-236	42U	2000mm	800mm	1000mm	1	Black Grey
20630-239	47U	2200mm	600mm	600mm	1	Black Grey
20630-240	47U	2200mm	600mm	800mm	1	Black Grey
20630-241	47U	2200mm	600mm	900mm	1	Black Grey
20630-242	47U	2200mm	600mm	1000mm	1	Black Grey
20630-245	47U	2200mm	800mm	600mm	1	Black Grey
20630-246	47U	2200mm	800mm	800mm	1	Black Grey
20630-247	47U	2200mm	800mm	900mm	1	Black Grey
20630-248	47U	2200mm	800mm	1000mm	1	Black Grey

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>
20630-195	24U	1200mm	600mm	900mm	1	Black Grey
20630-196	24U	1200mm	600mm	1000mm	1	Black Grey
20630-201	24U	1200mm	800mm	900mm	1	Black Grey
20630-202	24U	1200mm	800mm	1000mm	1	Black Grey
20630-205	29U	1400mm	600mm	900mm	1	Black Grey
20630-206	29U	1400mm	600mm	1000mm	1	Black Grey
20630-209	29U	1400mm	800mm	900mm	1	Black Grey
20630-210	29U	1400mm	800mm	1000mm	1	Black Grey
20630-213	33U	1600mm	600mm	900mm	1	Black Grey
20630-214	33U	1600mm	600mm	1000mm	1	Black Grey
20630-217	33U	1600mm	800mm	900mm	1	Black Grey
20630-218	33U	1600mm	800mm	1000mm	1	Black Grey
20630-221	38U	1800mm	600mm	900mm	1	Black Grey
20630-222	38U	1800mm	600mm	1000mm	1	Black Grey
20630-225	38U	1800mm	800mm	900mm	1	Black Grey
20630-226	38U	1800mm	800mm	1000mm	1	Black Grey
20630-251	52U	2450mm	600mm	1000mm	1	Black Grey
20630-254	52U	2450mm	800mm	1000mm	1	Black Grey

CatalogNumber	Rack Height	Height	Width	Depth	Package Quantity	Color
20630-253	52U	2450mm	600mm	1200mm	1	Black Grey
20630-256	52U	2450mm	800mm	1200mm	1	Black Grey

Table 2/2

Catalog Number	Color Code	Complies With	Frame Material	Type	Works With	Quick Ship
20630-252	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-255	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-231	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-232	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-237	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-238	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-243	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-244	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-249	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-250	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-193	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-194	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-199	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-200	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No

CatalogNumber	Color Code	Complies With	Frame Material	Type	Works With	Quick Ship
20630-203	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-204	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-207	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-208	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-211	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-212	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-215	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-216	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-219	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-220	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-223	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-224	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-227	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-228	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-229	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-230	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-233	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-234	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No

CatalogNumber	Color Code	Complies With	Frame Material	Type	Works With	Quick Ship
20630-235	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-236	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-239	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-240	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-241	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-242	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-245	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-246	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-247	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-248	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-195	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-196	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-201	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-202	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-205	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-206	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-209	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-210	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No

CatalogNumber	Color Code	Complies With	Frame Material	Type	Works With	Quick Ship
20630-213	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-214	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-217	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-218	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-221	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-222	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-225	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-226	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-251	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-254	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-253	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No
20630-256	RAL 7021	IEC 61587-1, IEC 61587-3	Steel	Mobile	Varistar CP	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**