

Hammer-On Flange Clip, Bottom Mount with Stud



CERTIFICATIONS



FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Captive threaded stud minimizes the need for additional hardware

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	Flange Thickness (FT)	Rod Size (RS)	Screw Diameter (Sc)	Screw Length (L)	Static Load 1 (F1)
EM58SM16R5	191044	8 - 14 mm	6	6	16mm	450N

CatalogNumber	Article Number	Flange Thickness (FT)	Rod Size (RS)	ScrewDiameter (Sc)	Screw Length (L)	Static Load 1 (F1)
EM1318SM	171855	21 - 28 mm	6	6	11mm	450N

Table 2/2

Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM58SM16R5	191044	330N	110N	
EM1318SM	171855	330N	110N	UL, cUL

DIAGRAMS

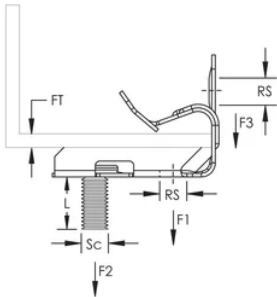

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

