


# TRC Four Pole Distribution Block, 630 A

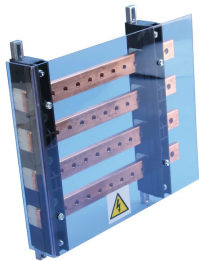

## CERTIFICATIONS



## FEATURES

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

## SPECIFICATIONS


| Catalog Number                        | TRC-630A                                                 |
|---------------------------------------|----------------------------------------------------------|
| Article Number                        | 563190                                                   |
| Material                              | Copper<br>Glass Fibre Reinforced Polyamide<br>Plexiglass |
| Max Working Voltage, IEC (Ui)         | 1000                                                     |
| Peak Short Circuit Current (Ipk)      | 84kA                                                     |
| Short Term Withstand Current (Icw) 1s | 52kA                                                     |

|                                 |                                                                         |
|---------------------------------|-------------------------------------------------------------------------|
| <b>Catalog Number</b>           | <b>TRC-630A</b>                                                         |
| Line Side Number of Connections | 1                                                                       |
| Load Side Number of Connections | 8                                                                       |
| Hole Size (HS)                  | 10 mm                                                                   |
| Thread Size (TS)                | M8                                                                      |
| Depth (D)                       | 60mm                                                                    |
| Height (H)                      | 338 - 390 mm                                                            |
| Width (W)                       | 340 mm                                                                  |
| A                               | 290 mm                                                                  |
| Unit Weight                     | 4.8 kg                                                                  |
| Flammability Rating             | UL® 94V-0                                                               |
| Complies With                   | IEC® 60439.1<br>IEC® 61439.1<br>IEC® 60695-2-11 (Glow Wire Test 960 °C) |

## ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

## DIAGRAMS

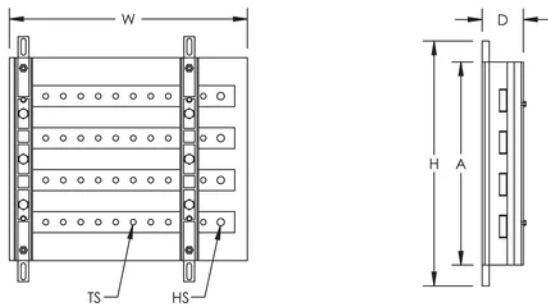

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**