


# U-profile Front Panel, Shieldable, D-Sub Cutouts

## Power Utilities

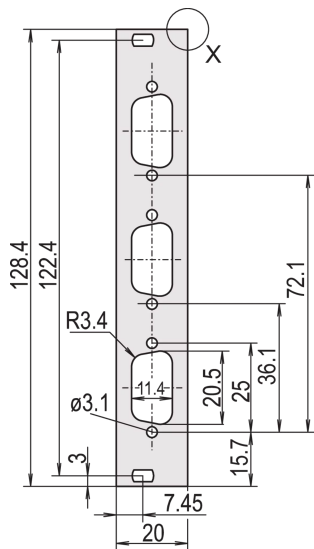

U-profile front panel with cutout for D-Sub connectors.  
Shieldable for textile EMC gasket.

## CERTIFICATIONS



## FEATURES

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

## SPECIFICATIONS

Table 1/3

| Catalog Number | Package Quantity | Mounting       | EMC Gasket Type | Front Finish | Rear Finish | Treated Edges |
|----------------|------------------|----------------|-----------------|--------------|-------------|---------------|
| 30849-749      | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |

| CatalogNumber | Package Quantity | Mounting       | EMC Gasket Type | Front Finish | Rear Finish | Treated Edges |
|---------------|------------------|----------------|-----------------|--------------|-------------|---------------|
| 30849-750     | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-751     | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-752     | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-753     | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-754     | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |
| 30849-755     | 5                | Screw-on Front | Textile         | Anodized     | Conductive  | No            |

Table 2/3

| Catalog Number | Complies With                   | EMC Shielding      | Height   | Material | Product Type | Rack Height |
|----------------|---------------------------------|--------------------|----------|----------|--------------|-------------|
| 30849-749      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |
| 30849-750      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |
| 30849-751      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |
| 30849-752      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |
| 30849-753      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |
| 30849-754      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |
| 30849-755      | IEC 60297-3-101, IEEE 1101.1/10 | No (Retrofittable) | 128.4 mm | Aluminum | Front Panel  | 3 U         |

Table 3/3

| Catalog Number | Rack Width | Type | Width |
|----------------|------------|------|-------|
|----------------|------------|------|-------|

|           |      |                            |       |
|-----------|------|----------------------------|-------|
| 30849-749 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-750 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-751 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-752 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-753 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-754 | 4 HP | Front Panel without Handle | 20 mm |
| 30849-755 | 4 HP | Front Panel without Handle | 20 mm |

## ADDITIONAL PRODUCT DETAILS

---

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**