


Z-Rail for Connector, DIN 41617, 31-pin

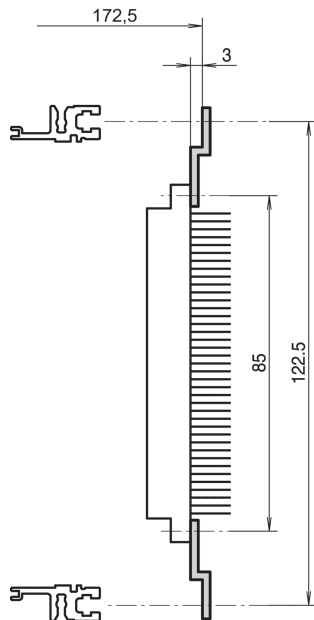

Z-rail for connector in accordance with DIN 41617, 31-pin.

CERTIFICATIONS

RoHS not found or type unknown

FEATURES

In conjunction with rear ST horizontal rails

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized
Works With:	Subracks; Cases
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
Product Type:	Z-Rail

Table 1/1

Catalog Number	Rack Width	Package Quantity	Length	Quick Ship
30819-783	60HP	1	304.8mm	No

Catalog Number	Rack Width	Package Quantity	Length	Quick Ship
30819-808	84HP	1	431.8mm	No

ADDITIONAL PRODUCT DETAILS

A threaded insert is required to secure the Z-rail on the horizontal rail.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE