


In-Line Cable Connector



CERTIFICATIONS

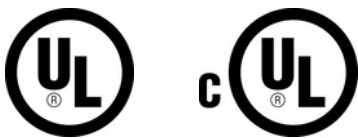

FEATURES

Cable splicer with four bolts for pressure on each cable

LPC513 is compatible with nVent ERICO Cu-Bond Round Conductors

SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2

Catalog Number	Material	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Width (W)	nVent ERICO Cu-Bond Conductor	Unit Weight
LPA513	Aluminum	19.05 mm	14.3 mm	82.55 mm		0.09 kg
LPC513	Copper	19.05 mm	14.3 mm	82.55 mm	CBSC8, CBSC10, CBSC13	0.17 kg

Table 2/2


Catalog Number	Complies With
----------------	---------------

LPA513	
LPC513	IEC® 62561-1

ADDITIONAL PRODUCT DETAILS

IEC compliance is valid only for nVent ERICO Cu-Bond Conductors listed.

DIAGRAMS

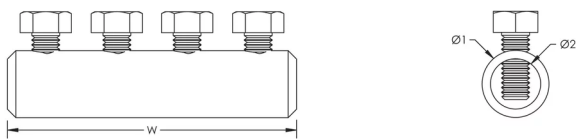

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE