

Flexible Plastic Conduit Clamp with Plug



FEATURES

Push-in installation of conduit

Flexible clamping design accommodates multiple conduit sizes using one clamp

Tool-free push-in installation after hole has been drilled into the concrete or brick

Low profile allows for installations in tight spaces

Non-flame propagating per IEC 61386-25

Passed 650°C glowing/hot-wire wire test per EN 60695-2

Halogen free

UV-stabilized

SPECIFICATIONS

Material: Polypropylene

Temperature: -10 to 85 °C


Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Length (L)	Width (W)	A	B
SCUSA1620	800025	16 - 20 mm	54mm	21.5 mm	21 mm	11.5 mm
SCUSA2025	800026	20 - 25 mm	61mm	26.1 mm	21 mm	14.3 mm
SCUSA2532	800027	25 - 32 mm	81mm	32.6 mm	21 mm	18.3 mm

CatalogNumber	Article Number	Outer Diameter (OD)	Length (L)	Width (W)	A	B
SCUSA3240	800028	32 - 42 mm	82mm	45 mm	21 mm	23 mm

Table 2/2		
Catalog Number	Article Number	Static Load
SCUSA1620	800025	170N
SCUSA2025	800026	170N
SCUSA2532	800027	170N
SCUSA3240	800028	170N

DIAGRAMS

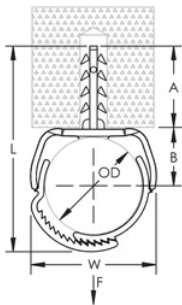

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

