


# Novastar Base/Plinth

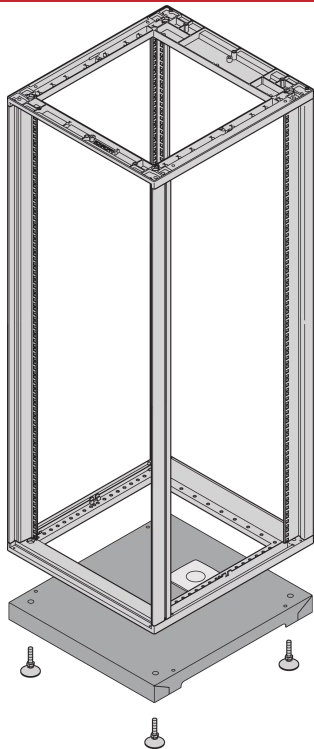

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

## CERTIFICATIONS

---



## FEATURES

---

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

## SPECIFICATIONS

<b>Height:</b>	45mm
<b>Product Type:</b>	Cabinet/Rack Base
<b>Material:</b>	Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Color	Color Code	Finish
27230-070	553mm	500mm	1	Black Grey	RAL 7021	Powder Coated
27230-071	553mm	600mm	1	Black Grey	RAL 7021	Powder Coated
27230-072	553mm	800mm	1	Black Grey	RAL 7021	Powder Coated
27230-076	900mm	900mm	1	Black Grey	RAL 7021	Powder Coated
27230-080	1000mm	1000mm	1	Black Grey	RAL 7021	Powder Coated

Table 2/2

Catalog Number	Type	Quick Ship
27230-070	Base Plinth	No
27230-071	Base Plinth	No
27230-072	Base Plinth	No
27230-076	Base Plinth	No
27230-080	Base Plinth	No

## ADDITIONAL PRODUCT DETAILS

Please order brush strip separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**