


Novastar Fan Top Cover

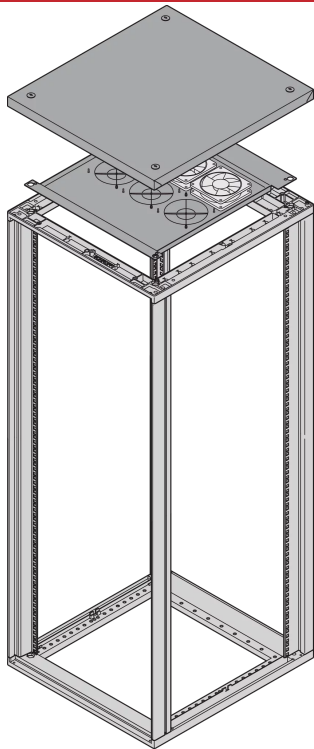

Top covers with fans are compact active cooling units which do not consume rack space. The Novastar fan top cover comes with C14 plug and grounding.

CERTIFICATIONS



FEATURES

Connecting cable 0.5 m, IEC C14 plug

St, RAL 7021

Top covers suitable for fan height 25 mm or 38 mm

Incl. grounding and cabling

Fan top cover (33 mm) raised

SPECIFICATIONS

Width:	553mm
Product Type:	Cabinet/Rack Top Cover
Material:	Steel

Table 1/2

Catalog Number	Depth	Package Quantity	Color	Color Code	Finish	Type
27230-081	500mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-083	800mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-085	500mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-086	600mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-087	800mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-082	600mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-094	900mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-095	1000mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-096	900mm	1	Black Grey	RAL 7021	Powder Coated	Fan
27230-097	1000mm	1	Black Grey	RAL 7021	Powder Coated	Fan

Table 2/2

Catalog Number	Certifications	Quick Ship
27230-081	RoHS, EAC	No
27230-083	RoHS, EAC	No
27230-085	EAC, RoHS	No
27230-086	RoHS, EAC	No

Catalog Number	Certifications	Quick Ship
27230-087	EAC, RoHS	No
27230-082	EAC, RoHS	No
27230-094	RoHS	No
27230-095	RoHS	No
27230-096	RoHS	No
27230-097	RoHS	No

ADDITIONAL PRODUCT DETAILS

Please order lifting eye separately if required.

Please order any additional fans (for increasing cooling capacity) separately.

If required, please order thermostat or speed controller separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE