


# PSU Front Panel

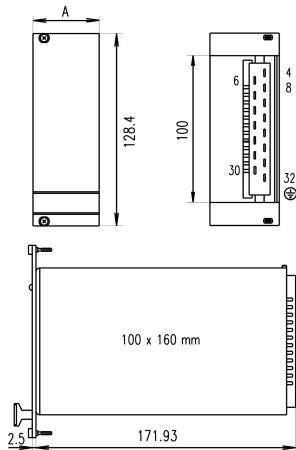

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

## CERTIFICATIONS



## FEATURES

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

## SPECIFICATIONS

**Accessory Type:** Front panel

Table 1/2

Catalog Number	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Height
21006-943	Aluminum	Anodized	Conductive	No	3U	128.4mm
21006-945	Aluminum	Anodized	Conductive	No	3U	128.4mm

CatalogNumber	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Height
21006-954	Aluminum	Anodized	Conductive	No	3U	128.4mm
21006-959	Aluminum	Anodized	Conductive	No	3U	128.4mm
31006-677	Aluminum	Anodized	Conductive	No	3U	128.4mm
21006-955	Aluminum	Anodized	Conductive	No	3U	128.4mm
21006-956	Aluminum	Anodized	Conductive	No	3U	128.4mm
21006-957	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-475	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-473	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-474	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-476	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-477	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-478	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-470	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-451	Aluminum	Anodized	Conductive	No	3U	128.4mm
21005-439	Aluminum	Anodized	Conductive	No	3U	128.4mm

Table 2/2

Catalog Number	Rack Width	Width	Depth	Package Quantity	Finish	Quick Ship
21006-943	6HP	30.14mm	2.5mm	1	Anodized	No
21006-945	8HP	40.3mm	2.5mm	1	Anodized	No

CatalogNumber	Rack Width	Width	Depth	Package Quantity	Finish	Quick Ship
21006-954	6HP	30.14mm	2.5mm	1	Anodized	No
21006-959	3HP	14.9mm	2.5mm	1	Anodized	No
31006-677	8HP	40.3mm	2.5mm	1	Anodized	No
21006-955	6HP	30.14mm	2.5mm	1	Anodized	No
21006-956	6HP	30.14mm	2.5mm	1	Anodized	No
21006-957	6HP	30.14mm	2.5mm	1	Anodized	No
21005-475	6HP	30.14mm	2.5mm	1	Anodized	No
21005-473	10HP	50.46mm	2.5mm	1	Anodized	No
21005-474	14HP	70.78mm	2.5mm	1	Anodized	No
21005-476	6HP	30.14mm	2.5mm	1	Anodized	No
21005-477	10HP	50.46mm	2.5mm	1	Anodized	No
21005-478	14HP	70.78mm	2.5mm	1	Anodized	No
21005-470	6HP	30.14mm	2.5mm	1	Anodized	No
21005-451	10HP	50.46mm	2.5mm	1	Anodized	No
21005-439	14HP	70.78mm	2.5mm	1	Anodized	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**