


Varistar CP Top Cover With Fan Tray

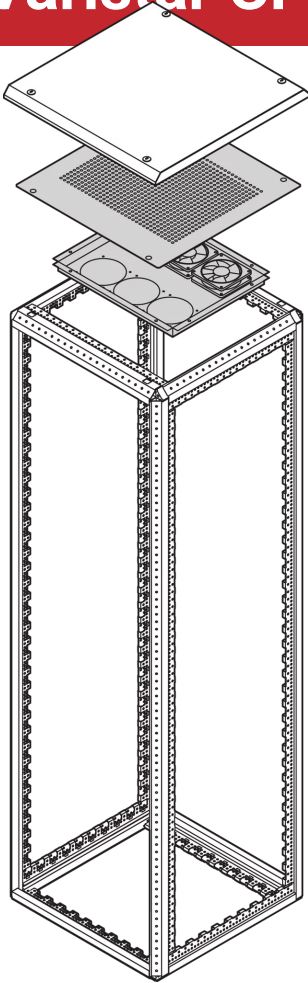

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

FEATURES

6 axial fans fitted

Schuko/IEC 60320 C12 plug

6 power saving axial fans fitted

Wide range power input 90-260 VAC

Speed control with 2 T° sensors

Alarm over T° and fan fail (Display panel at front & relay outputs)

Remote control over Modbus RTU or Guardian

SPECIFICATIONS

Product Type: Fan
Material: Steel

Table 1/3

Catalog Number	Width	Depth	Package Quantity	Voltage DC	Airflow	Noise Level
21630-777	600mm	600mm	1	24V	171m ³ /h	42.5dB(A)
21630-778	600mm	800mm	1	24V	171m ³ /h	42.5dB(A)
21630-783	800mm	600mm	1	24V	171m ³ /h	42.5dB(A)
21630-784	800mm	800mm	1	24V	171m ³ /h	42.5dB(A)
21630-785	800mm	900mm	1	24V	171m ³ /h	42.5dB(A)
21630-786	800mm	1000mm	1	24V	171m ³ /h	42.5dB(A)
21630-779	600mm	900mm	1	24V	171m ³ /h	42.5dB(A)
21630-780	600mm	1000mm	1	24V	171m ³ /h	42.5dB(A)
21630-781	600mm	1100mm	1	24V	171m ³ /h	42.5dB(A)
21630-782	600mm	1200mm	1	24V	171m ³ /h	42.5dB(A)
21630-787	800mm	1100mm	1	24V	171m ³ /h	42.5dB(A)
21630-788	800mm	1200mm	1	24V	171m ³ /h	42.5dB(A)
21630-790	600mm	600mm	1	24V	171m ³ /h	42.5dB(A)
21630-791	600mm	800mm	1	24V	171m ³ /h	42.5dB(A)
21630-792	600mm	900mm	1	24V	171m ³ /h	42.5dB(A)
21630-793	600mm	1000mm	1	24V	171m ³ /h	42.5dB(A)

CatalogNumber	Width	Depth	Package Quantity	Voltage DC	Airflow	Noise Level
21630-794	600mm	1100mm	1	24V	171m³/h	42.5dB(A)
21630-795	600mm	1200mm	1	24V	171m³/h	42.5dB(A)
21630-796	800mm	600mm	1	24V	171m³/h	42.5dB(A)
21630-797	800mm	800mm	1	24V	171m³/h	42.5dB(A)
21630-798	800mm	900mm	1	24V	171m³/h	42.5dB(A)
21630-799	800mm	1000mm	1	24V	171m³/h	42.5dB(A)
21630-800	800mm	1100mm	1	24V	171m³/h	42.5dB(A)
21630-801	800mm	1200mm	1	24V	171m³/h	42.5dB(A)

Table 2/3

Catalog Number	Max Static Pressure	Color	Color Code	Complies With	Finish	Protection Rating
21630-777	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-778	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-783	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-784	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-785	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-786	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-779	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-780	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20

CatalogNumber	Max Static Pressure	Color	Color Code	Complies With	Finish	Protection Rating
21630-781	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-782	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	
21630-787	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-788	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-790	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-791	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-792	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-793	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-794	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-795	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-796	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-797	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-798	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-799	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-800	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20
21630-801	68.1Pa	Black Grey	RAL 7021	IEC 61587-1	Powder Coated	IP20

Table 3/3

Catalog Number	Type	Works With	Quick Ship
21630-777	Top cover with fans	Varistar CP	No

Catalog Number	Type	Works With	Quick Ship
21630-778	Top cover with fans	Varistar CP	No
21630-783	Top cover with fans	Varistar CP	No
21630-784	Top cover with fans	Varistar CP	No
21630-785	Top cover with fans	Varistar CP	No
21630-786	Top cover with fans	Varistar CP	No
21630-779	Top cover with fans	Varistar CP	No
21630-780	Top cover with fans	Varistar CP	No
21630-781	Top cover with fans	Varistar CP	No
21630-782	Top cover with fans	Varistar CP	No
21630-787	Top cover with fans	Varistar CP	No
21630-788	Top cover with fans	Varistar CP	No
21630-790	Top cover with fans	Varistar CP	No
21630-791	Top cover with fans	Varistar CP	No
21630-792	Top cover with fans	Varistar CP	No
21630-793	Top cover with fans	Varistar CP	No
21630-794	Top cover with fans	Varistar CP	No
21630-795	Top cover with fans	Varistar CP	No
21630-796	Top cover with fans	Varistar CP	No

Catalog Number	Type	Works With	Quick Ship
21630-797	Top cover with fans	Varistar CP	No
21630-798	Top cover with fans	Varistar CP	No
21630-799	Top cover with fans	Varistar CP	No
21630-800	Top cover with fans	Varistar CP	No
21630-801	Top cover with fans	Varistar CP	No

ADDITIONAL PRODUCT DETAILS

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE