

25R Hex Rod Reducer



FEATURES

Threaded rod reducing coupling

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Rod Size 1 (RS1)	Rod Size 2 (RS2)	Length (L)	NB/DN
025R3725EG	Steel	Electrogalvanized	0.375	0.25	25.4mm	10 Max


Table 2/2

Catalog Number	Static Load
025R3725EG	1068N

ADDITIONAL PRODUCT DETAILS

Never use smaller rod sizes than the minimum rod sizes defined by applicable code.

DIAGRAMS

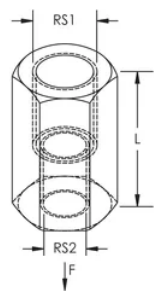

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

