


# nVent CADDY Pyramid EZ Rubber-Based Adjustable Support

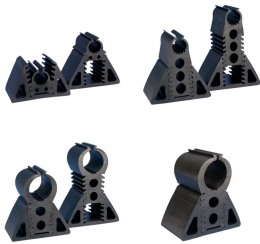

## CERTIFICATIONS



## FEATURES

Quick height adjustment accommodates for uneven roofs or sloped condensate lines

No tools or fasteners needed; fast snap-on installation

Design sheds water and helps reduce pipe corrosion

Roof-friendly; made of UV-stabilized EPDM material

## SPECIFICATIONS

**Material:** EPDM-SBR Rubber

Table 1/2

| Catalog Number | Article Number | NB/DN | Outer Diameter (OD) | Height (H)   | Length (L) | Width (W) |
|----------------|----------------|-------|---------------------|--------------|------------|-----------|
| RPSE1H24       | 182365         | 25    | 33 mm               | 45 - 102 mm  | 102mm      | 152 mm    |
| RPSE2H46       | 182375         | 50    | 60 mm               | 102 - 152 mm | 102mm      | 152 mm    |

| CatalogNumber | Article Number | NB/DN | Outer Diameter (OD) | Height (H)   | Length (L) | Width (W) |
|---------------|----------------|-------|---------------------|--------------|------------|-----------|
| RPSE4H46      | 182380         | 100   | 114 mm              | 100 - 150 mm | 102mm      | 240 mm    |

Table 2/2

| Catalog Number | Article Number | Unit Weight | Ultimate Static Load (F) |
|----------------|----------------|-------------|--------------------------|
| RPSE1H24       | 182365         | 0.91 kg     | 756N                     |
| RPSE2H46       | 182375         | 1.5 kg      | 1112N                    |
| RPSE4H46       | 182380         | 2.33 kg     | 3920N                    |

## ADDITIONAL PRODUCT DETAILS

Ultimate load at 1/4" (6.35 mm) deflection. Contact project or roofing engineer for maximum allowable load on individual project roof system.

## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

