

# Cathodic Bonding Strap, 5 Holes



## FEATURES

Allows electrical bonding across joints of steel pipe

Used on "Dresser Type" pipe couplings with two welds to the pipe and three to the coupling, made through the holes

Approximate electrical equivalent of a 1/0 conductor

Made of soft copper for easy forming

nVent ERICO Cadweld mold CAHAAAF and frame required to make connection

nVent ERICO Cadweld connections to pipe require a CA15 welding material

## SPECIFICATIONS

**Material:** Copper

Table 1/2


Catalog Number	Length (L)	Width (W)	Thickness (T)	Hole Size (HS)	A	B
CAB496A16B16	457.2mm	31.75 mm	1.59 mm	12.7 mm	101.6 mm	101.6 mm
CAB496A24B12	508mm	31.75 mm	1.59 mm	12.7 mm	152.4 mm	76.2 mm
CAB496A15B25	558.8mm	31.75 mm	1.59 mm	12.7 mm	95.25 mm	158.75 mm

Table 2/2

Catalog Number	C
----------------	---

CAB496A16B16	25.4 mm
CAB496A24B12	25.4 mm
CAB496A15B25	25.4 mm

## DIAGRAMS

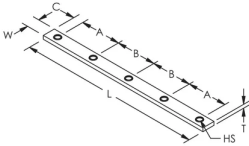

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**