


Female-Female Adaptor, Imperial Thread

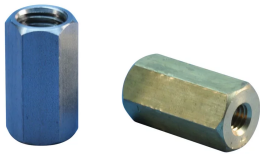

CERTIFICATIONS



FEATURES

Threaded adaptor with hexagonal body for ease of tightening

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Height (H)	Width (W)
LPA2932F2F	Aluminum		1/2" UNC	1/2" UNC	38.1 mm	19.1 mm
LPA2942F5F	Aluminum		1/2" UNC	5/8" UNC	38.1 mm	19.1 mm
LPA2955F5F	Aluminum		5/8" UNC	5/8" UNC	38.1 mm	19.1 mm
LPC2913F3F	Copper		3/8" UNC	3/8" UNC	38.1 mm	19.1 mm
LPC2923F2F	Copper		3/8" UNC	1/2" UNC	38.1 mm	19.1 mm


CatalogNumber	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Height (H)	Width (W)
LPC292L3F2F	Copper		3/8" UNC	1/2" UNC	38.1 mm	19.1 mm
LPC2932F2F	Copper		1/2" UNC	1/2" UNC	38.1 mm	19.1 mm
LPC2942F5F	Copper		1/2" UNC	5/8" UNC	38.1 mm	19.1 mm
LPC2955F5F	Copper		5/8" UNC	5/8" UNC	38.1 mm	19.1 mm
LPC295L5F5F	Copper	Tinned	5/8" UNC	5/8" UNC	38.1 mm	19.1 mm
LPS2923F2F	Stainless Steel 304 (EN 1.4301)		3/8" UNC	1/2" UNC	38.1 mm	19.1 mm
LPS2932F2F	Stainless Steel 304 (EN 1.4301)		1/2" UNC	1/2" UNC	38.1 mm	19.1 mm
LPS2942F5F	Stainless Steel 304 (EN 1.4301)		1/2" UNC	5/8" UNC	38.1 mm	19.1 mm
LPS2955F5F	Stainless Steel 304 (EN 1.4301)		5/8" UNC	5/8" UNC	38.1 mm	19.1 mm

Table 2/2

Catalog Number	Unit Weight	Certifications
LPA2932F2F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2942F5F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2955F5F	0.02 kg	
LPC2913F3F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2923F2F	0.02 kg	
LPC292L3F2F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2932F2F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC

Catalog Number	Unit Weight	Certifications
LPC2942F5F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2955F5F	0.02 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC295L5F5F	0.02 kg	
LPS2923F2F	0.02 kg	
LPS2932F2F	0.02 kg	
LPS2942F5F	0.02 kg	
LPS2955F5F	0.02 kg	

DIAGRAMS

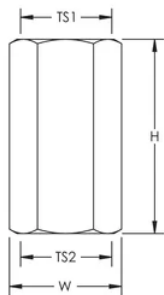

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE