

Glued Clip Kit



FEATURES

Glued rail clips eliminate the need to drill any support where the clips need to be fixed, respecting the support integrity and improving safety

No tools needed; pre-applied hard-bonding glue makes installation easy and efficient

Resistant to corrosion-causing agents, including U.V., weather conditions, oil, greases, gasoline, solvents, rain and water

Helps increase lifetime of attached cable, reducing total project cost

Versatile base can accommodate different sizes of clips for different sizes of conductors and is usable for longitudinal or transversal cable applications

Each kit includes one container of adhesive suitable for a 10.1 oz. (300 ml) dispensing gun

Dispensing gun not included

SPECIFICATIONS

Temperature: -40 to 93 °C

Table 1/2

Catalog Number	Article Number	Diameter (Ø)	Length (L)	Width (W)	Hole Size (HS)	Number of Base Plates Included
GCHSC67	186005	6 - 7 mm	100mm	40 mm	7 mm	30
GCHSC1011	186025	10 - 11 mm	100mm	40 mm	7 mm	30
GCHSC1214	186035	12 - 14 mm	100mm	40 mm	7 mm	30


CatalogNumber	Article Number	Diameter (Ø)	Length (L)	Width (W)	Hole Size (HS)	Number ofBase PlatesIncluded
GCHSC1518	186045	15 - 18 mm	100mm	40 mm	7 mm	30
GCHSC1924	186055	19 - 24 mm	100mm	40 mm	7 mm	30
GCHSC2530	186065	25 - 30 mm	100mm	40 mm	7 mm	30
GCHSC78	187745	7 - 8 mm	100mm	40 mm	7 mm	30
GCHSC89	186015	8 - 9 mm	100mm	40 mm	7 mm	30
GCHSC910	187785	9 - 10 mm	100mm	40 mm	7 mm	30

Table 2/2			
Catalog Number	Article Number	Number of Clips Included	Clips Per Base Plate
GCHSC67	186005	120	4 Max
GCHSC1011	186025	120	4 Max
GCHSC1214	186035	120	4 Max
GCHSC1518	186045	90	3 Max
GCHSC1924	186055	90	3 Max
GCHSC2530	186065	60	2 Max
GCHSC78	187745	120	4 Max
GCHSC89	186015	120	4 Max
GCHSC910	187785	120	4 Max

ADDITIONAL PRODUCT DETAILS

3-clip configuration shown. 1- to 4-clip configurations also available.

DIAGRAMS

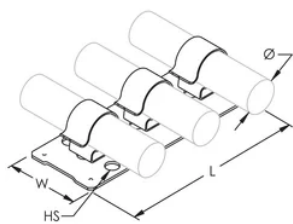

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE