


Front Panel, Shielded, Side Hinged, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

CATALOG NUMBER

20848-611

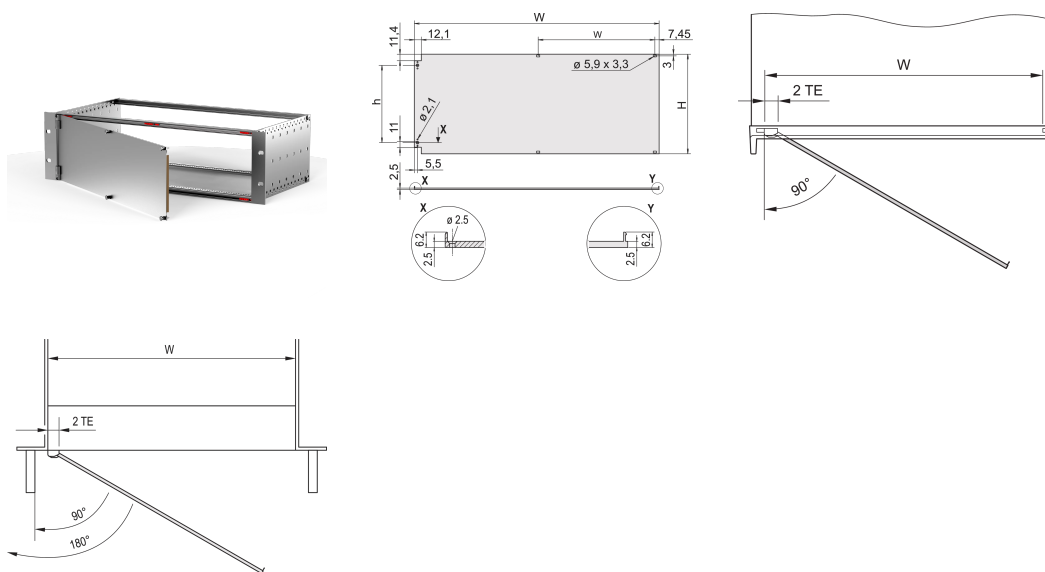

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICATIONS



FEATURES

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails


Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUCT ATTRIBUTES

Rack Height: 3U
Package Quantity: 1
Accessory Type: Front panel
Mounting: Hinged, Side
Gasket Type: Textile EMC
Front Finish: Anodized
Rear Finish: Conductive
Treated Edges: No
Depth (D): 2.5mm
EMC Shielding: No (Retrofittable)
Finish: Anodized; Passivated
Height (H): 128.4mm
Material: Aluminum
Product Type: Front Panel
Rack Width: 84HP
Type: Front Panel without Handle
Width (W): 426.4mm
Net Weight: 0.56kg

DIAGRAMS

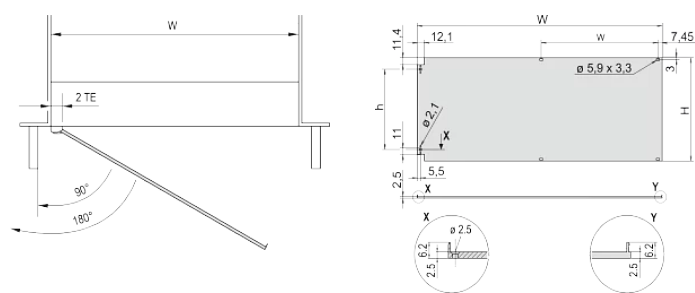

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE