

# nVent CADDY Speed Link SLK with Wedge Anchor



## FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

## SPECIFICATIONS

<b>Wire Rope Diameter:</b>	2 mm
<b>Static Load Safety Factor:</b>	5:1
<b>Drill Bit Diameter:</b>	6mm
<b>Drill Hole Depth:</b>	31mm
<b>Embedment Depth:</b>	25 mm Min
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Polypropylene;Zinc Alloy


Table 1/2

Catalog Number	Article Number	Wire Rope Length	Length (L)	Height (H)	Width (W)	Thickness (T)
SLK2L2WA6	196734	2m	54mm	55 mm	19 mm	12.5 mm
SLK2L5WA6	196736	5m	63.5mm	55 mm	19 mm	12.5 mm

CatalogNumber	Article Number	Wire Rope Length	Length (L)	Height (H)	Width (W)	Thickness (T)
SLK2L3WA6	196735	3m	54mm	55 mm	19 mm	12.5 mm

Table 2/2			
Catalog Number	Article Number	Angle (a)	Static Load
SLK2L2WA6	196734	90 ° Max	300N
SLK2L5WA6	196736	90 ° Max	440N
SLK2L3WA6	196735	90 ° Max	300N

### DIAGRAMS

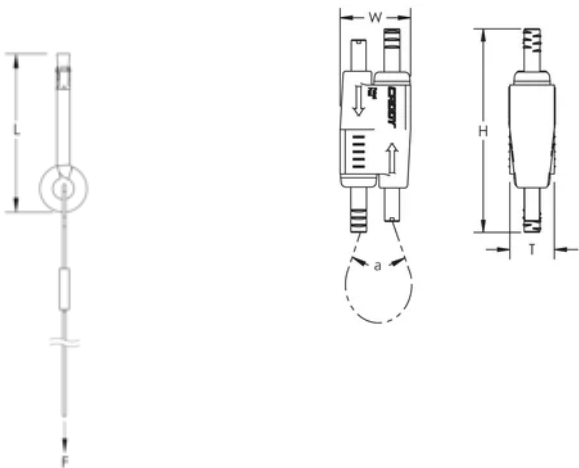

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

