


# 19" Front Panel With Holes for Handles

## Data Solutions

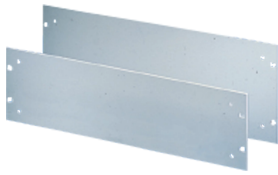

Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U dimensions.

### CERTIFICATIONS



### FEATURES

19" front panels have additional holes for mounting of handles

### SPECIFICATIONS

- Rack Width:** 95HP
- Material:** Aluminum
- Accessory Type:** Front panel
- Product Type:** Front Panel

Table 1/3

Catalog Number	Rack Height	Depth (D)	Handle Type	Finish	Mounting	Package Quantity
30219-161	1U	3mm	Front Handle	Anodized	Screw-on Front	1

CatalogNumber	Rack Height	Depth (D)	Handle Type	Finish	Mounting	Package Quantity
40304-050	1U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-162	2U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-163	3U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-164	4U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-165	5U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-166	6U		Front Handle	Anodized	Screw-on Front	1
40304-051	2U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-052	3U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-053	4U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-054	5U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-055	6U	3mm	Front Handle	Anodized	Screw-on Front	1

Table 2/3

Catalog Number	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Height (H)	Type
30219-161	Anodized	Anodized	No	No	43.6mm	19" Front Panel
40304-050	Anodized	Anodized	Yes	No	43.6mm	19" Front Panel
30219-162	Anodized	Anodized	No	No	88.1mm	19" Front Panel
30219-163	Anodized	Anodized	No	No	132.5mm	19" Front Panel
30219-164	Anodized	Anodized	No	No	177mm	19" Front Panel

CatalogNumber	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Height (H)	Type
30219-165	Anodized	Anodized	No	No	221.4mm	19" Front Panel
30219-166	Anodized	Anodized	No	No	265.9mm	19" Front Panel
40304-051	Anodized	Anodized	Yes	No	88.1mm	19" Front Panel
40304-052	Anodized	Anodized	Yes	No	132.5mm	19" Front Panel
40304-053	Anodized	Anodized	Yes	No	177mm	19" Front Panel
40304-054	Anodized	Anodized	Yes	No	221.4mm	19" Front Panel
40304-055	Anodized	Anodized	Yes	No	265.9mm	19" Front Panel

Table 3/3

Catalog Number	Width (W)
30219-161	483mm
40304-050	483mm
30219-162	483mm
30219-163	483mm
30219-164	483mm
30219-165	483mm
30219-166	483mm
40304-051	483mm
40304-052	483mm
40304-053	483mm

Catalog Number	Width (W)
40304-054	483mm
40304-055	483mm

## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**