

Theft-Deterrent Grounding Busbar, Post Mount Assembly



CERTIFICATIONS



FEATURES

Mounts to a Schedule 40 pipe or post without cutting or drilling the pipe

Accepts standard telecommunication grounding lugs (lugs not included)

Includes 14 Standard Spacers (TDSGAS)


SPECIFICATIONS

Table 1/2

| Catalog Number | Material | Finish | Spacer Thickness | Length (L) | A | Fence Post Size, Nominal |
|----------------|--|--------|------------------|------------|---------|--------------------------|
| TDSGAPC14 | Copper, Stainless Steel 304 (EN 1.4301), Stainless Steel 18-8 (EN 1.4305), Nylon | Tinned | 6.4mm | 266mm | 25.4 mm | 1 1/2" - 2" |

| Table 2/2 | | | | |
|----------------|---|---------------------|---------------------|---------------------|
| Catalog Number | Fence Post Outside Diameter, Actual (Ø) | Thread Size 1 (TS1) | Thread Size 2 (TS2) | Thread Size 3 (TS3) |
| TDSGAPC14 | 48.00 - 63.5 mm | 3/8" UNC | 5/16" UNC | 5/16" UNC |

DIAGRAMS

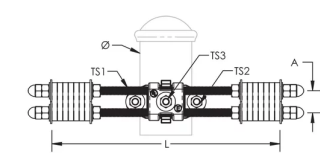

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE