

Vise Clamp for Telecom



FEATURES

Used to bond messenger wire to ground tap conductors

When clamp is tightened, the piercing teeth puncture the insulation on the messenger wire, forming a positive ground connection without stripping the cable

SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Height (H)	Width (W)	Depth (D)	Diameter (Ø)
EVC167P	Copper Alloy, Stainless Steel 304 (EN 1.4301)	Tinned	41.3 mm	31.8 mm	25.4mm	3.7 - 7.93 mm

Table 2/2

Catalog Number	Thread Size (TS)	Unit Weight
EVC167P	5/16" UNC	0.1 kg

DIAGRAMS

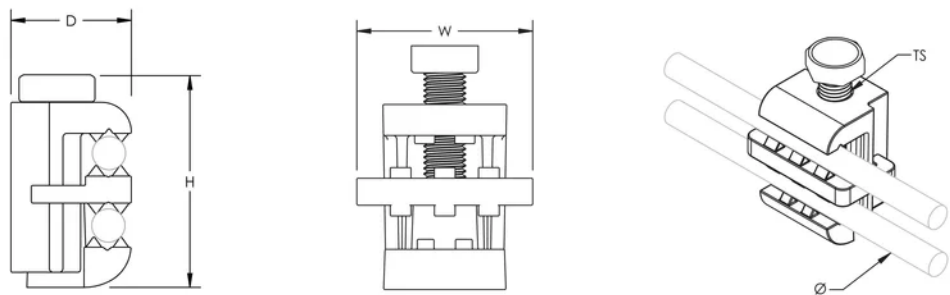

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE