

# T-Series Vertical Filler Material Kit



T-Series vertical filler material kits contain the following: Filler material, two vertical packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

## FEATURES

Simplifies ordering

Used to splice the same diameter bars

All components are for one-time use

## SPECIFICATIONS

Table 1/1

| Catalog Number | Sleeve          | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada |
|----------------|-----------------|--------------------|----------------|--------------------|
| RBT121018B     | Standard Length | 38 mm              | #12            |                    |
| RBT4101B       | Standard Length | 12 mm              | #4             | 10M                |
| RBT5101B       | Standard Length | 16 mm              | #5             | 15M                |
| RBT6101B       | Standard Length | 20 mm              | #6             | 20M                |
| RBT7101B       | Standard Length | 22 mm              | #7             |                    |
| RBT81011B      | Extended Length | 25 mm              | #8             | 25M                |
| RBT8101B       | Standard Length | 25 mm              | #8             | 25M                |

| Catalog Number | Sleeve          | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada |
|----------------|-----------------|--------------------|----------------|--------------------|
| RBT91011B      | Extended Length | 28 mm              | #9             | 30M                |
| RBT9101B       | Standard Length | 28 mm              | #9             | 30M                |
| RBT10911B      | Extended Length | 32 mm              | #10            |                    |
| RBT1091B       | Standard Length | 32 mm              | #10            |                    |
| RBT111011B     | Extended Length | 36 mm              | #11            | 35M                |
| RBT11101B      | Standard Length | 36 mm              | #11            | 35M                |
| RBT14101B      | Standard Length | 43 mm              | #14            | 45M                |
| RBT1891B       | Standard Length | 57 mm              | #18            | 55M                |

## ADDITIONAL PRODUCT DETAILS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Vertical Top Packing, (3) Vertical Bottom Packing, (4) Pouring Basin Ceramic Guide Tube, and (5) Crucible Ceramic and Disk.

| Filler Material Kit Components |                 |                      |                                       |                                  |
|--------------------------------|-----------------|----------------------|---------------------------------------|----------------------------------|
| Filler Material Kit            | Filler Material | Packing (2 Required) | Pouring Basin Ceramic Insert and Disk | Pouring Basin Ceramic Guide Tube |
| RBT4101B                       | RBF40           | RBS354710 RBS354710  | RBS5037                               | RBS5039                          |
| RBT5101B                       | RBF40           | RBS354710 RBS35475   | RBS5037                               | RBS5038                          |
| RBT6101B                       | RBF50           | RBS35473.5 RBS35477  | RBS5037                               | RBS5038                          |
| RBT7101B                       | RBF50           | RBS35474 RBS35478    | RBS5037                               | RBS5038                          |
| RBT81011B                      | RBF70           | RBS354710 RBS35475   | RBS5037                               | RBS5038                          |
| RBT8101B                       | RBF55           | RBS354710 RBS35475   | RBS5037                               | RBS5038                          |
| RBT91011B                      | RBF90           | RBS354711 RBS35475.5 | RBS5037                               | RBS5038                          |
| RBT9101B                       | RBF80           | RBS354711 RBS35475.5 | RBS5037                               | RBS5038                          |
| RBT10911B                      | RBF105          | RBS354712 RBS35476   | RBS5037                               | RBS5038                          |
| RBT1091B                       | RBF90           | RBS354712 RBS35476   | RBS5037                               | RBS5038                          |
| RBT111011B                     | RBF125          | RBS354712 RBS35476   | RBS5037                               | RBS5038                          |
| RBT11101B                      | RBF105          | RBS354712 RBS35476   | RBS5037                               | RBS5038                          |
| RBT121018B                     | RBF180          | RBS354715 RBS35477   | RBS5037                               | RBS5038                          |
| RBT14101B                      | RBF195          | RBS354715 RBS35477   | RBS5037                               | RBS5039                          |
| RBT1891B                       | RBF270          | RBS354720 RBS35479   | RBS5037                               | RBS5039                          |

## DIAGRAMS

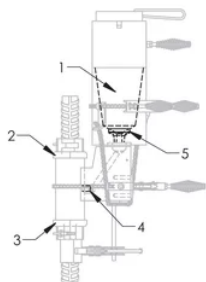

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**