


PropacPRO Front Panel, Full Width, Unshielded, 2 U, 42 HP, 2 mm, Al, Anodized, Untreated Edges

CATALOG NUMBER

20850-128

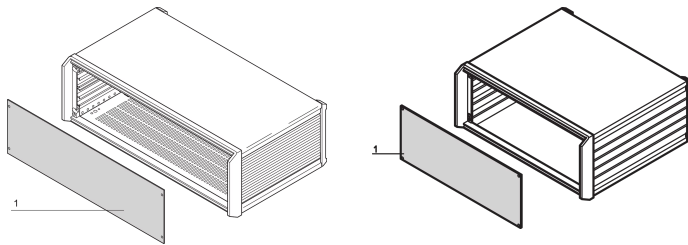

The front panel, full width for PropacPRO Case mounts to the frame of the case.

CERTIFICATIONS



FEATURES

Al panel, 2.0 mm (84 HP 2.5 mm)

PRODUCT ATTRIBUTES

Rack Height: 2U

Rack Width: 42HP

Accessory Type: Front panel

Package Quantity: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: No

Depth: 2mm

Finish: Anodized

Height: 84mm

Material: Aluminum

Product Type: Front Panel

Width: 238.7mm

Net Weight: 0.14kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE