

# Front Panel 1 U, Horizontal Rail Mounting



The 1 U front panel enables a user to cover the 1 U section in a 4 U PropacPRO case, RatiopacPRO 5 U (1-3-1) and EuropacPRO 4 U. The panel will be assembled to the threaded inserts of the horizontal rails.

## CERTIFICATIONS



## FEATURES

Mounts on horizontal rails (upper, lower)

## SPECIFICATIONS

|                        |                                    |
|------------------------|------------------------------------|
| <b>Material:</b>       | Aluminum                           |
| <b>Finish:</b>         | Anodized; Passivated               |
| <b>Product Family:</b> | RatiopacPRO; PropacPRO; EuropacPRO |
| <b>Accessory Type:</b> | Front panel                        |
| <b>Product Type:</b>   | Front Panel                        |

Table 1/2


| Catalog Number | Rack Height | Height (H) | Rack Width | Width (W) | Depth (D) | Package Quantity |
|----------------|-------------|------------|------------|-----------|-----------|------------------|
| 20850-423      | 1U          | 39.5mm     | 28HP       | 141.9mm   | 2.5mm     | 1                |

| CatalogNumber | Rack Height | Height (H) | Rack Width | Width (W) | Depth (D) | Package Quantity |
|---------------|-------------|------------|------------|-----------|-----------|------------------|
| 20850-424     | 1U          | 39.5mm     | 42HP       | 213mm     | 2.5mm     | 1                |
| 20850-425     | 1U          | 39.5mm     | 63HP       | 319.7mm   | 2.5mm     | 1                |
| 20850-426     | 1U          | 39.5mm     | 84HP       | 426.4mm   | 2.5mm     | 1                |

Table 2/2

| Catalog Number | Front Finish | Rear Finish | Treated Edges | Quick Ship |
|----------------|--------------|-------------|---------------|------------|
| 20850-423      | Anodized     | Conductive  | No            | No         |
| 20850-424      | Anodized     | Conductive  | No            | No         |
| 20850-425      | Anodized     | Conductive  | No            | No         |
| 20850-426      | Anodized     | Conductive  | No            | No         |

## DIAGRAMS

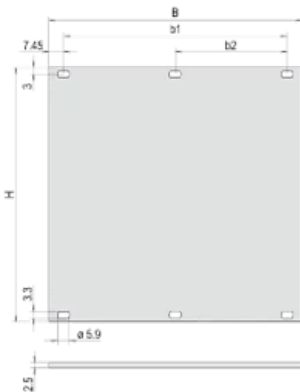

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**