


Novastar Frame, Universal Heavy-Duty

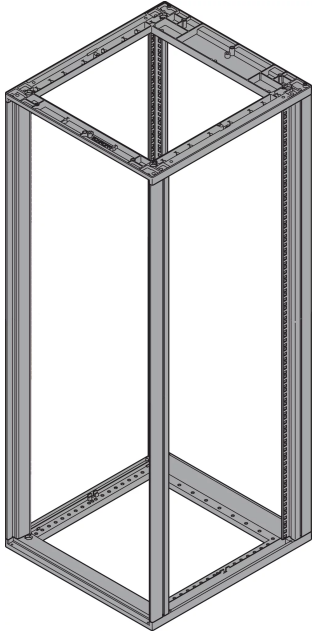

Asthetic aluminum extruded frame with 400 kg static load capacity. 19" upright built into the frame.

CERTIFICATIONS



FEATURES

Novastar Frame, Universal Heavy-Duty

Aluminium profile, RAL 7021, including grounding

Static load-carrying capacity 400 kg

SPECIFICATIONS

Static Load:	400kg
Frame Material:	Aluminum
Material:	Aluminum
Product Type:	Cabinet/Rack Frame

Table 1/2

Catalog Number	Rack Height	Height	Width	Depth	Package Quantity	Color
28230-052	47U	2145mm	553mm	900mm	1	Black Grey
28230-053	47U	2145mm	553mm	1000mm	1	Black Grey
28230-057	12U	589mm	553mm	500mm	1	Black Grey
28230-058	12U	589mm	553mm	600mm	1	Black Grey
28230-059	12U	589mm	553mm	800mm	1	Black Grey
28230-107	12U	589mm	553mm	900mm	1	Black Grey
28230-108	12U	589mm	553mm	1000mm	1	Black Grey
28230-109	16U	767mm	553mm	500mm	1	Black Grey
28230-110	16U	767mm	553mm	600mm	1	Black Grey
28230-111	16U	767mm	553mm	800mm	1	Black Grey
28230-112	16U	767mm	553mm	900mm	1	Black Grey
28230-113	16U	767mm	553mm	1000mm	1	Black Grey
28230-114	20U	945mm	553mm	500mm	1	Black Grey
28230-115	20U	945mm	553mm	600mm	1	Black Grey
28230-116	20U	945mm	553mm	800mm	1	Black Grey
28230-117	20U	945mm	553mm	900mm	1	Black Grey
28230-118	20U	945mm	553mm	1000mm	1	Black Grey
28230-119	25U	1167mm	553mm	500mm	1	Black Grey

CatalogNumber	Rack Height	Height	Width	Depth	Package Quantity	Color
28230-167	25U	1167mm	553mm	600mm	1	Black Grey
28230-168	25U	1167mm	553mm	800mm	1	Black Grey
28230-169	25U	1167mm	553mm	900mm	1	Black Grey
28230-170	25U	1167mm	553mm	1000mm	1	Black Grey
28230-171	34U	1567mm	553mm	500mm	1	Black Grey
28230-172	34U	1567mm	553mm	600mm	1	Black Grey
28230-173	34U	1567mm	553mm	800mm	1	Black Grey
28230-174	34U	1567mm	553mm	900mm	1	Black Grey
28230-175	34U	1567mm	553mm	1000mm	1	Black Grey
28230-176	38U	1745mm	553mm	500mm	1	Black Grey
28230-177	38U	1745mm	553mm	600mm	1	Black Grey
28230-178	38U	1745mm	553mm	800mm	1	Black Grey
28230-179	38U	1745mm	553mm	900mm	1	Black Grey
28230-180	38U	1745mm	553mm	1000mm	1	Black Grey
28230-181	43U	1967mm	553mm	500mm	1	Black Grey
28230-182	43U	1967mm	553mm	600mm	1	Black Grey
28230-183	43U	1967mm	553mm	800mm	1	Black Grey
28230-184	43U	1967mm	553mm	900mm	1	Black Grey

CatalogNumber	Rack Height	Height	Width	Depth	Package Quantity	Color
28230-185	43U	1967mm	553mm	1000mm	1	Black Grey
28230-186	47U	2145mm	553mm	500mm	1	Black Grey
28230-187	47U	2145mm	553mm	600mm	1	Black Grey
28230-188	47U	2145mm	553mm	800mm	1	Black Grey
28230-221	29U	1345mm	553mm	500mm	1	Black Grey
28230-222	29U	1345mm	553mm	600mm	1	Black Grey
28230-223	29U	1345mm	553mm	800mm	1	Black Grey
28230-224	29U	1345mm	553mm	900mm	1	Black Grey
28230-225	29U	1345mm	553mm	1000mm	1	Black Grey

Table 2/2

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-052	RAL 7021	Powder Coated	Universal	RoHS	No
28230-053	RAL 7021	Powder Coated	Universal	RoHS	No
28230-057	RAL 7021	Powder Coated	Universal	RoHS	No
28230-058	RAL 7021	Powder Coated	Universal	RoHS	No
28230-059	RAL 7021	Powder Coated	Universal	RoHS	No
28230-107	RAL 7021	Powder Coated	Universal	RoHS	No
28230-108	RAL 7021	Powder Coated	Universal	RoHS	No
28230-109	RAL 7021	Powder Coated	Universal	RoHS	No

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-110	RAL 7021	Powder Coated	Universal	RoHS	No
28230-111	RAL 7021	Powder Coated	Universal	RoHS	No
28230-112	RAL 7021	Powder Coated	Universal	RoHS	No
28230-113	RAL 7021	Powder Coated	Universal	RoHS	No
28230-114	RAL 7021	Powder Coated	Universal	RoHS	No
28230-115	RAL 7021	Powder Coated	Universal	RoHS	No
28230-116	RAL 7021	Powder Coated	Universal	RoHS	No
28230-117	RAL 7021	Powder Coated	Universal	RoHS	No
28230-118	RAL 7021	Powder Coated	Universal	RoHS	No
28230-119	RAL 7021	Powder Coated	Universal	RoHS	No
28230-167	RAL 7021	Powder Coated	Universal	RoHS	No
28230-168	RAL 7021	Powder Coated	Universal	RoHS	No
28230-169	RAL 7021	Powder Coated	Universal	RoHS	No
28230-170	RAL 7021	Powder Coated	Universal	RoHS	No
28230-171	RAL 7021	Powder Coated	Universal	RoHS	No
28230-172	RAL 7021	Powder Coated	Universal	RoHS	No
28230-173	RAL 7021	Powder Coated	Universal	RoHS	No
28230-174	RAL 7021	Powder Coated	Universal	RoHS	No

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-175	RAL 7021	Powder Coated	Universal	RoHS	No
28230-176	RAL 7021	Powder Coated	Universal	RoHS	No
28230-177	RAL 7021	Powder Coated	Universal	RoHS	No
28230-178	RAL 7021	Powder Coated	Universal	RoHS	No
28230-179	RAL 7021	Powder Coated	Universal	RoHS	No
28230-180	RAL 7021	Powder Coated	Universal	RoHS	No
28230-181	RAL 7021	Powder Coated	Universal	RoHS	No
28230-182	RAL 7021	Powder Coated	Universal	RoHS	No
28230-183	RAL 7021	Powder Coated	Universal	RoHS	No
28230-184	RAL 7021	Powder Coated	Universal	RoHS	No
28230-185	RAL 7021	Powder Coated	Universal	RoHS	No
28230-186	RAL 7021	Powder Coated	Universal	RoHS	No
28230-187	RAL 7021	Powder Coated	Universal	RoHS	No
28230-188	RAL 7021	Powder Coated	Universal	RoHS	No
28230-221	RAL 7021	Powder Coated	Universal		No
28230-222	RAL 7021	Powder Coated	Universal		No
28230-223	RAL 7021	Powder Coated	Universal		No
28230-224	RAL 7021	Powder Coated	Universal		No

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-225	RAL 7021	Powder Coated	Universal		No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE